

TDK item description 60726YP251K4EAS


Applications For Distribution Lines

Feature SF6 Gas Insulated SF6 Gas (Insulation Type)

Series FD

Status  Production

Brand TDK

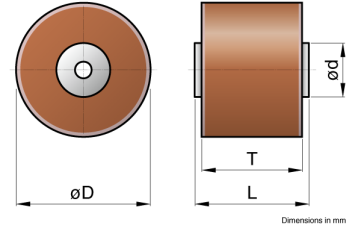

Size

D	34.00mm ±1.00mm
L	39.00mm ±1.00mm
T	35.00mm +1.00,-2.00mm
d	10.00mm ±0.50mm
Screw Thread	ISO M4

Electrical Characteristics

Capacitance	250pF ±10%
Rated Voltage	25kVAC
Withstanding Voltage (Nom.)	40kVAC
AC Corona Starting Voltage [3pC] (Min.)	32kVAC
Lightning Impulse Withstand Voltage (Min.)	
Temperature Characteristic	Y5P(±10%)
Dissipation Factor (Max.)	0.3%
Insulation Resistance (Min.)	10000MΩ

Other

Operating Temperature Range	-30 to 85°C
Storage Temperature Range	-30 to 85°C
Packing	Box