



Lithium Coin Cell - CR 2325

- Reliable energy for your application
- Standard cells and customized packs
- ESD protection
- UL recognized
- Battery Certification Experts



RoHS compliant



Pb free



REACH compliant



Conflict mineral free


Technical Data Sheet · CR 2325

SPECIFICATIONS


| | |
|-------------------------|----------------------|
| Nominal Voltage | 3V |
| Jauch part number | 249999 (1pc blister) |
| Nominal Capacity | 220 mAh |
| Standard Load | 15 kΩ |
| Standard Current | 0.2 mA |
| Max. Continuous Current | 3 mA |
| Max. Pulse Current | 18 mA |
| Operating Temperature | -30°C to +70°C* |
| Weight | Approx. 3.2 gr. |
| Chemistry | Li/MnO ₂ |
| UL1642 | MH62838 |

* In applications where the battery is exposed to temperatures >70°C, please contact Jauch.


DIMENSIONS

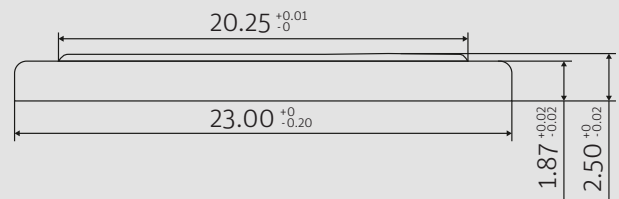

DISCHARGE CHARACTERISTICS

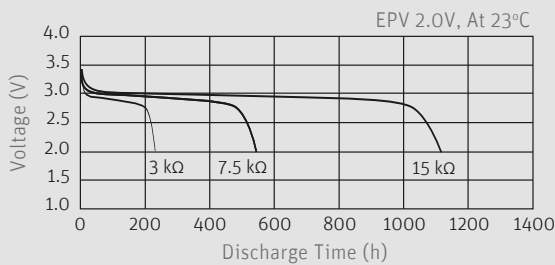

TEMPERATURE CHARACTERISTICS

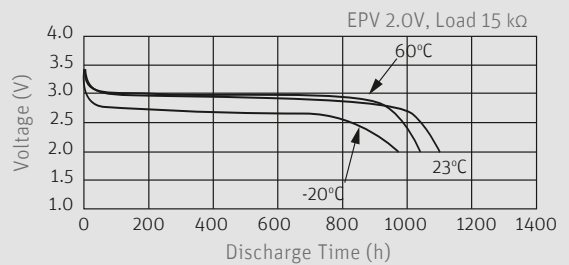

Wide assortment of mounting options, including through hole, surface mount and wire terminals.

Contact Jauch for more information
batterytechnology@jauch.com