

TA292411



Sample image

Order symbol : TA292411

Product nr : 5814003

Description : Enclosure, ABS


Remarks : Grey cover

EAN : 6418074060754

El. number :

- Finland : 3435688
- Denmark : 8212035069
- Sweden : 5814003

Including : Base with PUR gasket and screws for mounting plate/DIN-rail. cover with polyamide cover screws and plastic hinges.

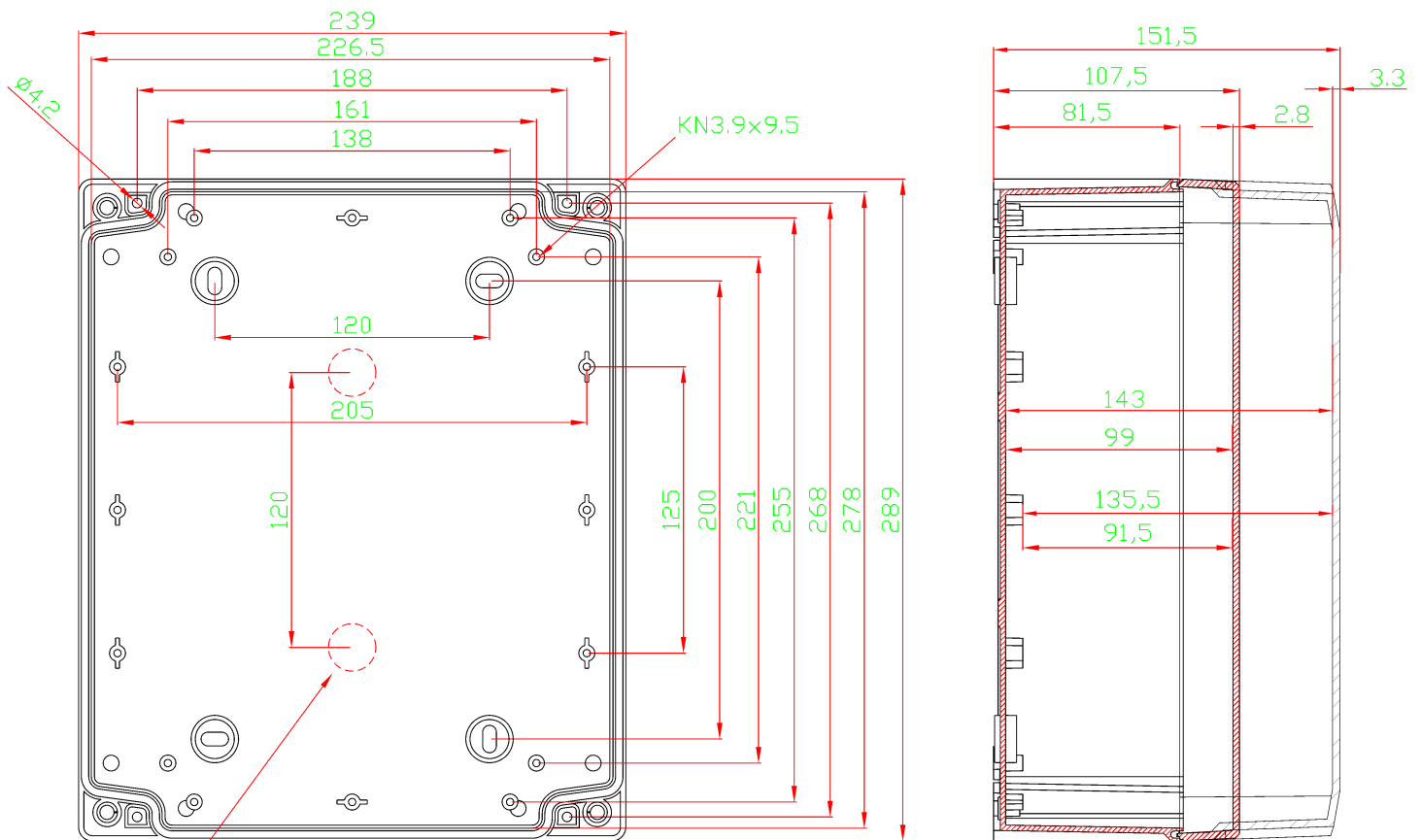

2xM20 knock out

Dimensions :

	Height	Width	Depth
mm :	289	239	107
inch :	11.38	9.41	4.21

Materials :

Material : ABS

Temperatures :

Temperature °F (continuous) : -40 ... 140

Accessories :

MP 2924	Mounting plate, for enclosures:
DR 215	DIN-35 Mounting rail, for enclosures: (215 x 35 x 1)
DR 265	DIN-35 Mounting rail, for enclosures: (265 x 35 x 1)
FP 10674	Wall fastening lug (2 pcs) incl. screws

Ratings :

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK07;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	-
Flammability Rating :	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C :	650C

Certificates :

Certificate FI 40343