




Part Number : [1062830245](#)

Product Description : QSFP-DD MPO-to-MPO Patch Cord, 50/125µm, 3.00mm, MultiMode, 16 Fiber, OM4, 5.0m Length, Aqua Cable

Series Number : 106283

Status : Active

Product Category : Fiber Optic Cable Assemblies

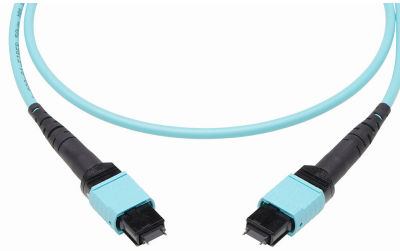

Documents & Resources

Drawings

[Drawing 1062830245_sd.pdf](#)

Specifications

[Application Specification 1062840501-000.pdf](#)

[Product Specification 1062830201-000.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Fiber Optic Cable Assemblies
Series	106283
Description	QSFP-DD MPO-to-MPO Patch Cord, 50/125µm, 3.00mm, MultiMode, 16 Fiber, OM4, 5.0m Length, Aqua Cable
Connector to Connector	MPO/APC-to-MPO/APC
Mode	Multimode
Product Family	Optoelectronic Solutions
Product Name	MPO,QSFP-DD Optical Cables
UPC	195842047785

Physical

Boot Type	Straight
Cable Length	5.0m
Cable Size	3.00mm
Fiber (Core/Cladding)	50/125µm
Single Ended	No
Wire/Cable Type	16 Fiber OM4 Bend-insensitive Plenum