




**Part Number :** [1062836339](#)

**Product Description :** QSFP-DD MPO-to-(8)  
LCD Uniboot Jumper Cable Assembly,  
50/125µm, 3.00mm, MultiMode, 16 Fiber,  
OM4, 5.0m Length, Aqua Cable

**Series Number :** 106283

**Status :** Active

**Product Category :** Fiber Optic Cable  
Assemblies

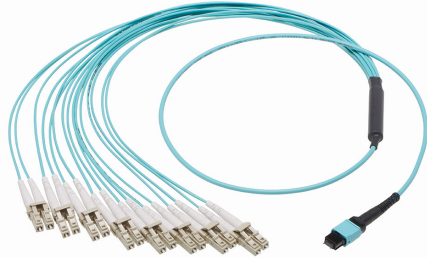

---

## Documents & Resources

### Drawings

[Drawing 1062836339\\_sd.pdf](#)

---

## Product Environment Compliance

### Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

### EU RoHS Certificate of Compliance

---

## Part Details

## General

Status	Active
Category	Fiber Optic Cable Assemblies
Series	106283
Description	QSFP-DD MPO-to-(8) LCD Uniboot Jumper Cable Assembly, 50/125µm, 3.00mm, MultiMode, 16 Fiber, OM4, 5.0m Length, Aqua Cable
Connector to Connector	MPO/APC-to-(8) LCD Uniboot
Mode	Multimode
Product Family	Optoelectronic Solutions
Product Name	MPO, QSFP-DD Optical Cables, LCD Uniboot
UPC	196823414220

## Physical

Boot Type	Straight
Cable Length	5.0m
Cable Size	3.00mm
Fiber (Core/Cladding)	50/125µm
Single Ended	No
Wire/Cable Type	16 Fiber OM4 Plenum