




Part Number : [1062836382](#)

Product Description : QSFP-DD MPO-to-(8)
LCD Uniboot Jumper Cable Assembly,
9/125µm, 3.00mm, Singlemode, 16 Fiber,
3.0m Length, Yellow Cable

Series Number : 106283

Status : Active

Product Category : Fiber Optic Cable
Assemblies

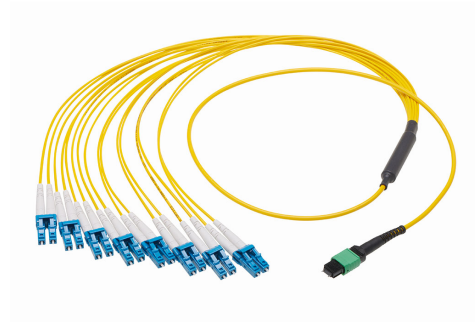

Documents & Resources

Drawings

[Drawing 1062836382_sd.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Fiber Optic Cable Assemblies
Series	106283
Description	QSFP-DD MPO-to-(8) LCD Uniboot Jumper Cable Assembly, 9/125µm, 3.00mm, Singlemode, 16 Fiber, 3.0m Length, Yellow Cable
Connector to Connector	MPO/APC-to-(8) LCD Uniboot
Mode	Singlemode
Product Family	Optoelectronic Solutions
Product Name	MPO,QSFP-DD Optical Cables,LCD Uniboot
UPC	196823749261

Physical

Boot Type	Straight
Cable Length	5.0m
Cable Size	3.00mm
Fiber (Core/Cladding)	9/125µm
Single Ended	No
Wire/Cable Type	16 Fiber SM Bend-insensitive Plenum