


EG1315 SERIES SLIDE SWITCH

ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS



APPLICATIONS / MARKETS

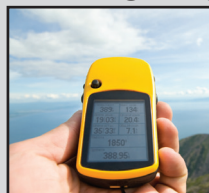

Handheld Devices



Wearable Electronics




Internet of Things



Smart Home



Telecommunication

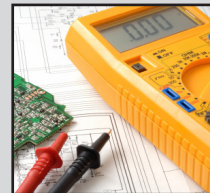

Testing Equipment

RoHS

SPECIFICATIONS

Contact Rating: 25mA @ 24VDC
Electrical Life: 10,000 Cycles
Contact Resistance: 70mΩ Max
Insulation Resistance: 1MΩ Min @ 100VDC
Dielectric Strength: 100VAC for 1 Minute
Operating Temperature: -20°C to 70°C
Storage Temperature: -40°C to 85°C
Travel: 1.50mm
Contact Arrangement: SP3T
Actuation Force: POS.2 to POS.1 or POS.3 = 200±150gF
POS.3 or POS.1 to POS.2 = 150±100gF

FEATURES & BENEFITS

- Surface mount PC board design
- 1.50mm travel
- Compact design
- 150-200 gram force
- SP3T function

PART NUMBER CONFIGURATOR

Series



EG1315

Actuator
Option



A - 1.30mm

Function
Option



A - SP3T

Specifications subject to change without notice 7.13.2018



E-SWITCH®

www.e-switch.com


800.867.2717

1


EG1315 SERIES SLIDE SWITCH

BODY DIMENSIONS

FUNCTION	POS. 1	POS. 2	POS. 3
A - SP3T	ON	ON	ON
TERMINAL CLOSURE	1-3	2-3	3-4



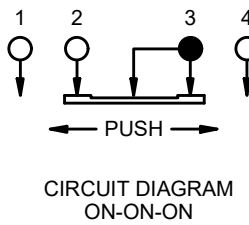


SCHEMATIC

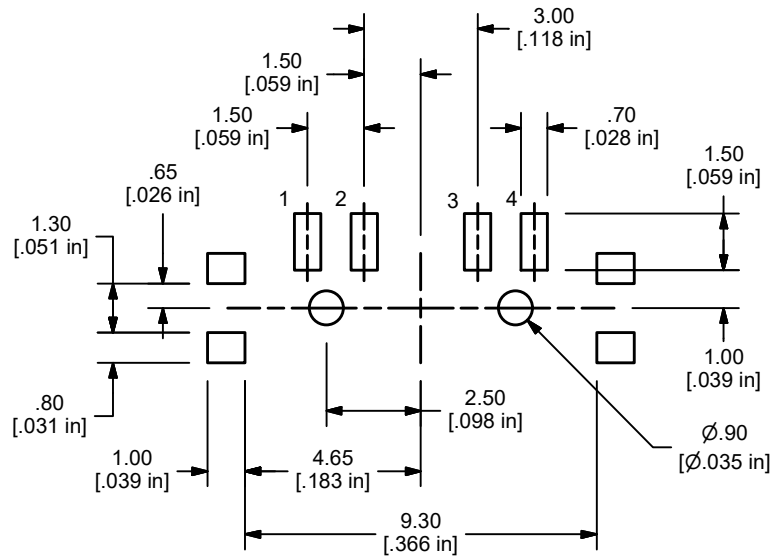

SURFACE MOUNT PCB LAYOUT

A - SP3T - FUNCTION OPTION

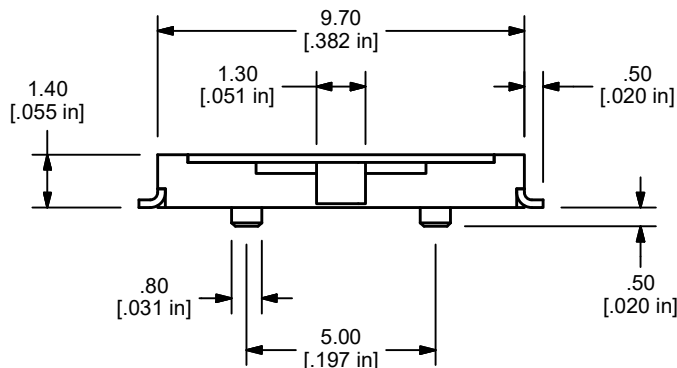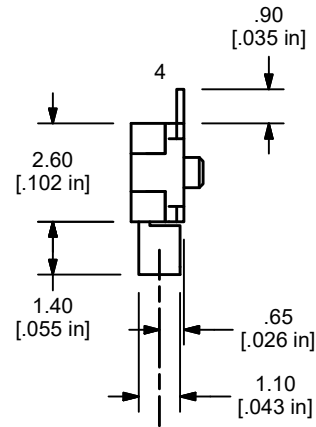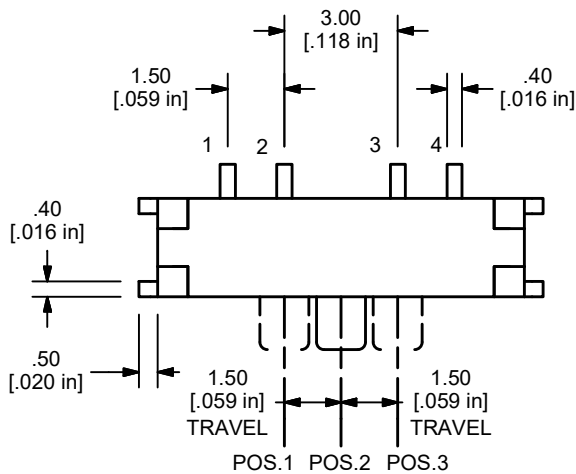

ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS