


PXMBNI12FPM17AFLM16001 Datasheet

Product Name // PXMBNI12FPM17AFLM16001

 [View Product Page](#)

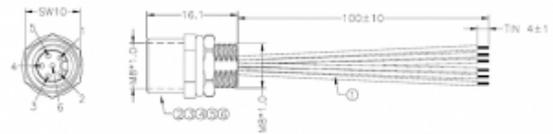

// Product Description:

-  Material=Metal
-  Pins=4
-  Max Rating=30Vac
-  Ingress Protection=IP67
-  Operating Temperature= -25Å°C to +85Å°C
-  Contact Resistance=5?
-  Insulation Resistance=>100M?
-  Mechanical Cycles=100 (min)

// General Information:

Product Display Title:	M12 Front and Rear Panel Mount Flying Lead
Product Family:	Circular Automation Connectors
Product Series:	M12 Series
Body Material:	Brass - Nickel Plated
Contact Type:	Plug Contact
Number Of Contacts:	17 Contacts

// Product PDF Links

 [M12 Series automation connectors...](#)