


# PX0105S02GY Datasheet

**Product Name // 2 Contacts Male Standard Rectangular Grey Connector - PEC**

[View Product Page](#)

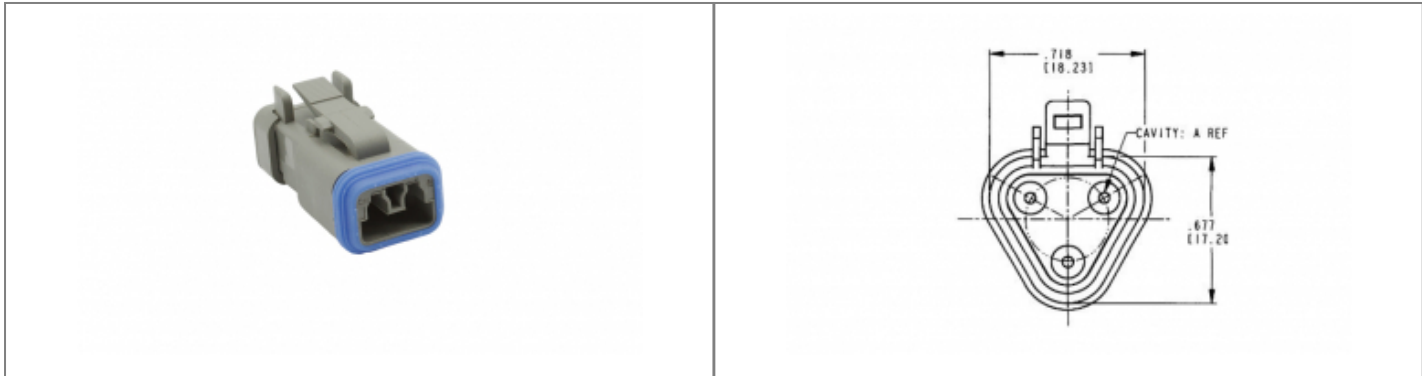

**// Product Description:**

- ⊕ 2 Contacts Male Standard Rectangular Grey Connector - PEC
- ⊕ Protective End Cap (PEC) Included
- ⊕ Water and dustproof to IP68 when mated with compatible connector
- ⊕ Mate with PX0101 Series, as appropriate
- ⊕ Wedgelocks provided
- ⊕ Crimp Terminals
- ⊕ Mechanical Cycles = 100 (min)
- ⊕ Operating Temperature = -25Å°C to +120Å°C

**// General Information:**

Product Display Title:	2 Contacts Male Standard Rectangular Grey Connector - PEC
Product Family:	Rectangular Connectors
Product Series:	Standard Rectangular Connectors
Body Colour:	Grey
Body Material:	Polycarbonate/Polybutylene Terephthalate (PC/PBT)
Body Material Type:	Plastic Body
Contact Type:	Socket Contact
Coupling Type:	Snap-in
Current Max:	13A
Ip Rating:	IP68
Max Operating Temperature:	+120°C
Min Operating Temperature:	-40°C
Number Of Contacts:	2 Contacts
Voltage Max:	250V

**// Product PDF Links**

[Rectangular Connector Datasheet](#)