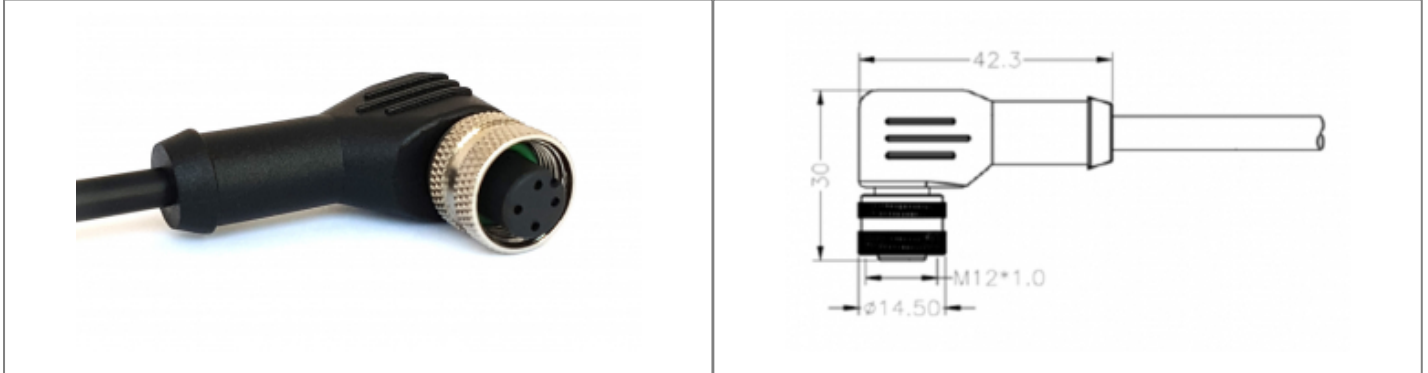


PXPPVC12RAF12ACL030PVC Datasheet

Product Name // M12 Series A Code PVC Right-Angle Overmould Flex Cable Connector 12 Contact Socket Pre-Wired With 3M PVC Jacket Cable

[View Product Page](#)


// Product Description:

- ⬡ M12 Series Right-Angle Overmould Flex Body Connectors
- ⬡ Water and dustproof to IP67 when mated with compatible connector
- ⬡ Pin or Socket
- ⬡ 3, 4, 5, 8, 12 Contact (3, 8, 12 Contact are A Code, 4 Contact are choice of A Code or D Code, 5 Contact are choice of A Code or B Code)
- ⬡ Overmould cable Termination with choice of lead lengths and choice of PVC or PUR jacket cable, depending on part code
- ⬡ Choice of Sealing Caps available separately to maintain IP rating of unmated connectors
- ⬡ Mate with M12 Series Inline Body and Panel Mount Connectors, depending on part code

// General Information:

Product Display Title:	M12 Series Right-Angle Overmould Flex Body Connectors
Product Family:	Circular Automation Connectors
Product Series:	M12 Series
Body Material:	PVC
Contact Type:	Socket Contact
Coupling Type:	Screw
Current Max:	1.5A
Diameter Over Coupling Ring Mm:	20mm
Function:	Right Angle Flex Connector Single Ended Cable
Ip Rating:	IP67
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	12 Contacts
Pin Layout Code:	A Code
Sheath Material:	PVC
Thread Size:	M12 x 1
Voltage Max:	30V

// Product PDF Links

[M12 Series automation connectors...](#)


Have a question or project enquiry you'd like to talk to us about?

[Click Here To Contact Us](#)