
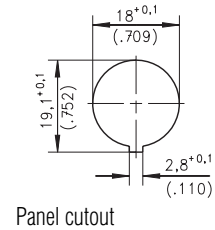


C 091 A

Female receptacle,
screw locking,
front mounting

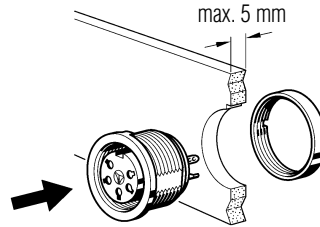

Panel cutout

Description	Drawing	No. of cont.	Part Number solder termination			Part No. Crimp termination ¹⁾		
			Contact plating silver ring nut	hex nut	Contact plating gold ²⁾ ring nut			
Female receptacle, termination: solder or crimp, panel mounting with ring or hex nut, contact plating: silver or gold. solder area: tin plated		2	T 3203 000	T 3203 009	T 3203 018	–		
		3 DIN	T 3263 000	T 3263 009	T 3263 018	T 3263 550		
		4 IEC	T 3303 000	T 3303 009	T 3303 018	T 3303 550		
		5	T 3363 000	T 3363 009	T 3363 018	T 3363 550		
		5 S DIN	T 3363 010	T 3359 009	T 3359 018	T 3359 550		
		6 DIN	T 3403 000	T 3403 009	T 3403 018	T 3403 550		
		7	T 3478 000	T 3478 009	T 3478 018	T 3478 550		
		7 DIN	T 3487 000	T 3487 009	T 3487 018 ⁴⁾	T 3487 550		
		8 DIN	T 3507 000	T 3507 009	T 3507 018	T 3507 550 ⁴⁾		
		12	T 3638 000	T 3638 009	T 3638 004	–		
		14	T 3653 000	T 3653 009	T 3653 004	–		
		Female receptacle, termination: straight dip solder, pin length 15 mm from flange, panel mounting with ring nut, contact plating: silver or gold. solder area: tin plated		2	T 3203 300 ⁴⁾	–	–	–
				3 DIN	T 3263 300	–	–	–
				4 IEC	T 3303 300	–	–	–
5	T 3363 300			–	–	–		
5 S DIN	T 3359 300			–	–	–		
6 DIN	T 3403 300			–	–	–		
7	T 3478 300			–	–	–		
7 DIN	T 3487 300			–	–	–		
8 DIN	T 3507 300			–	–	–		
12	–			–	T 3638 304	–		
14	–			–	T 3653 304 ⁴⁾	–		
Female receptacle, termination: straight dip solder, pin length 19 mm from flange, panel mounting with ring nut, contact plating: silver. solder area: tin plated				2	T 3203 320 ⁴⁾	–	–	–
				3 DIN	T 3263 320	–	–	–
				4 IEC	T 3303 320	–	–	–
		5	T 3363 320	–	–	–		
		5 S DIN	T 3359 320	–	–	–		
		6 DIN	T 3403 320	–	–	–		
		7	T 3478 320	–	–	–		
		7 DIN	T 3487 320	–	–	–		
		8 DIN	T 3507 320	–	–	–		
		12	–	–	–	–		
		14	–	–	–	–		
		Female receptacle, termination: straight dip solder, pin length 24 mm from flange, panel mounting with ring nut, contact plating: silver. solder area: tin plated		2	T 3203 330 ⁴⁾	–	–	–
				3 DIN	T 3263 330	–	–	–
				4 IEC	T 3303 330	–	–	–
5	T 3363 330			–	–	–		
5 S DIN	T 3359 330			–	–	–		
6 DIN	T 3403 330			–	–	–		
7	T 3478 330			–	–	–		
7 DIN	T 3487 330			–	–	–		
8 DIN	T 3507 330			–	–	–		
12	–			–	–	–		
14	–			–	–	–		

¹⁾ Please order crimp contacts separately, see page 46 ²⁾ See remark page 9

⁴⁾ Available upon request. Min. order qty.100 pcs/type.