




BU-41500320XX

(Cable Assembly Coaxial SMA Right Angle to SMA Right Angle Male to Male RG-316)

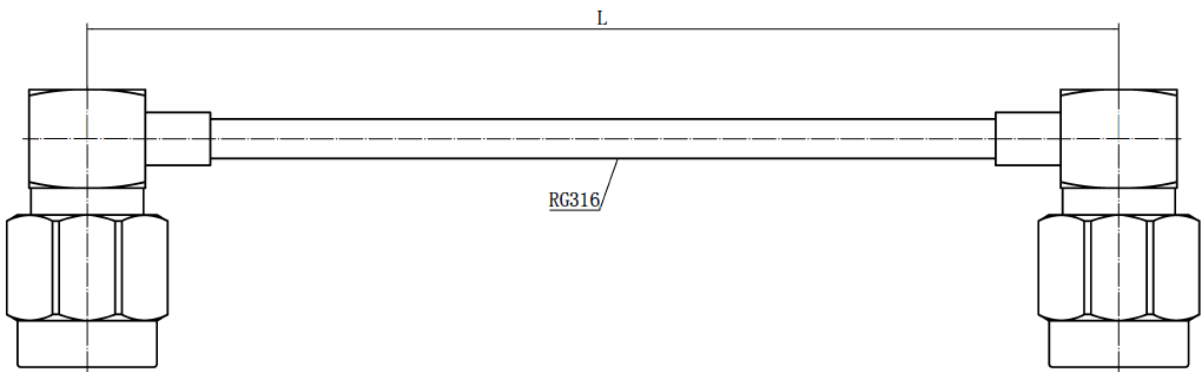

Mueller Electric Company
2850 Gilchrist Rd. Bld 5A
Akron, OH 44305

www.muellerelectric.com

Toll Free: 800.955.2629
Phone: 330.780.2525
Fax: 330.780.2524

Electrical Ratings

Electrical ratings of a cable assembly are determined by the limiting connector type and cable size.

Connector	Cable	Connector Impedance (Ohms)	Frequency (GHz)	VSWR	Working Voltage (At Sea Level)
SMA	RG-316	50	0-6	1.25 MAX	335V

Product Attributes

Gender	Male to Male
Style	SMA to SMA
1st Connector	Gold Plated SMA Male Plug Right Angle
2nd Connector	Gold Plated SMA Male Plug Right Angle
Features	Shielded
Operating Temperature	-65°C (-85°F) to 150°C (302°F)
BU-4150032006	6" (152.40 mm)
BU-4150032012	12" (304.8 mm)
BU-4150032018	18" (457.2 mm)
BU-4150032024	24" (609.6 mm)
BU-4150032036	36" (914.4 mm)
BU-4150032048	48" (1219.2 mm)
BU-4150032M1.5	1.5M (59.1")
BU-4150032MM250	250mm (9.8")
RoHS 3 Compliant	