

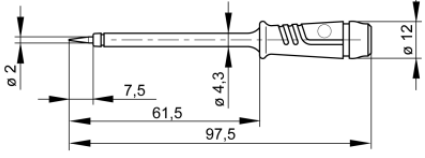


Test probes

PRUEF 2



Product	PRUEF 2
description	Test tip with shatter-proof insulated sleeve. Insulation and oxide layers can be penetrated by the slender stainless steel tip. 4mm diameter brass socket connection. Accessory (optional): tip protector, IC-tap SS 260
operating instruction	BA419
article-no. / *colour	9733681xx <div style="display: flex; justify-content: space-around; align-items: center;"> <div style="text-align: center;">  00 black </div> <div style="text-align: center;">  01 red </div> </div>
drawing	
technical data	
connection	unsprung socket 4 mm
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	1 A
material socket	brass
housing material	PP
temperature range acc. To IEC61010 ⁽¹⁾	-20 °C to +80 °C
inflammability class acc. to UL 94 (only valid for basic material of housing)	HB

4 mm system

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022