

## Cat6 Patch Cables


### Slim Cat6 U/UTP LSZH Patch Cables

Part No: 2994 - (Length) + (Colour) see chart

Available in 10 Colours with 13 different length options the Videk range of Slim Cat6 cables are designed to support high performance & high density networks. Manufactured to Cat6 standards using 28AWG LSZH cable and high quality plugs featuring a snag free boot these cables measure nearly half the diameter of traditional Cat6 cable allowing for a clutter free networking environment.

#### Features & Benefits

- Slim Cat6 cables helps create a clutter free networking environment
- Designed for High Performance & High Density Networks
- Supports POE/POE++ applications
- Featuring LSZH stranded UTP cable along with 50 micron gold RJ45 connectors
- Fully backward compatible with Cat.5/Cat.5E networks
- Outer jacket diameter 3.8mm (+/-0.2mm)

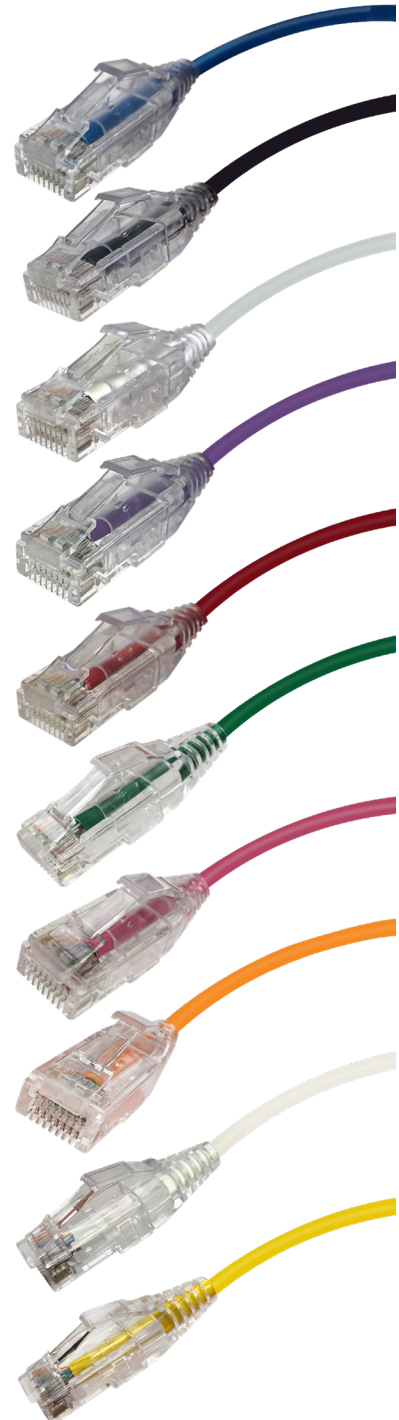


## Cat6 Patch Cables

### Slim Cat6 U/UTP LSZH Patch Cables

Part No: 2994 - (Length) + (Colour) see chart

Length available: 0.15m to 15m

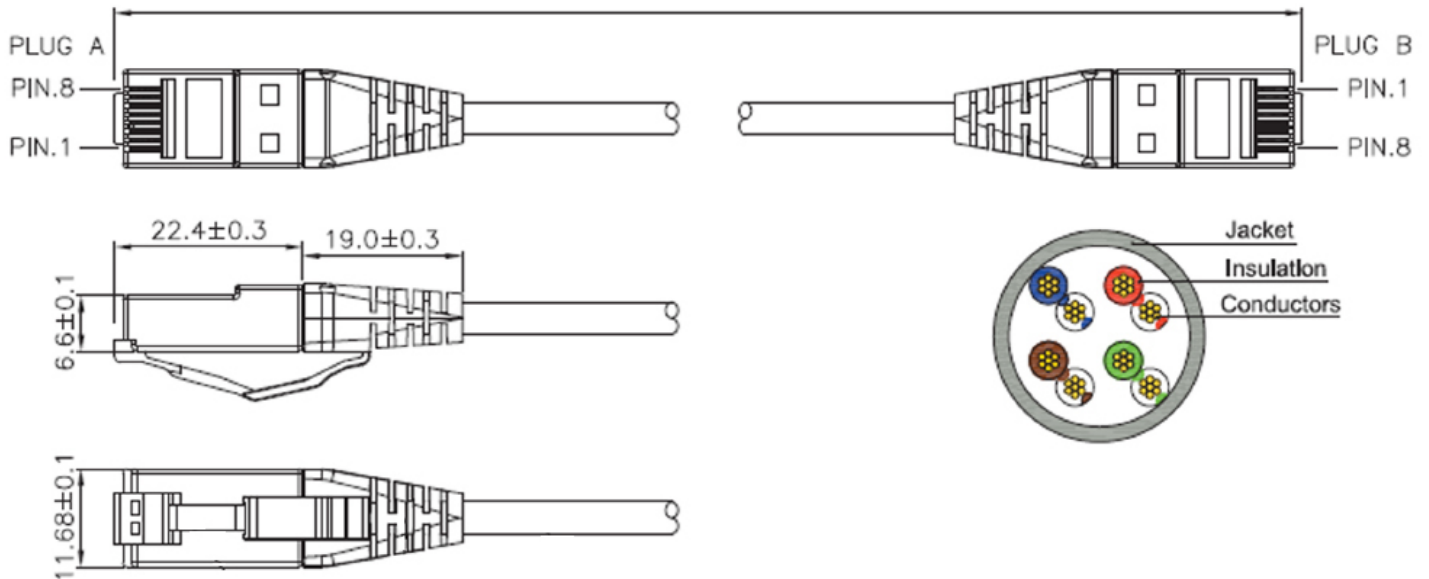






# Cat6 Patch Cables

## Slim Cat6 U/UTP LSZH Patch Cables

Part No: 2994 - (Length) + (Colour) see chart

### Part Number Chart





Length	Blue 	Black 	Grey 	Purple 	Red 
0.15 Metre	2994-0.15B	2994-0.15BK	2994-0.15GY	2994-0.15PR	2994-0.15R
0.2 Metre	2994-0.2B	2994-0.2BK	2994-0.2GY	2994-0.2PR	2994-0.2R
0.3 Metre	2994-0.3B	2994-0.3BK	2994-0.3GY	2994-0.3PR	2994-0.3R
0.5 Metre	2994-0.5B	2994-0.5BK	2994-0.5GY	2994-0.5PR	2994-0.5R
0.75 Metre	2994-0.75B	2994-0.75BK	2994-0.75GY	2994-0.75PR	2994-0.75R
1 Metre	2994-1B	2994-1BK	2994-1GY	2994-1PR	2994-1R
1.5 Metre	2994-1.5B	2994-1.5BK	2994-1.5GY	2994-1.5PR	2994-1.5R
2 Metre	2994-2B	2994-2BK	2994-2GY	2994-2PR	2994-2R
3 Metre	2994-3B	2994-3BK	2994-3GY	2994-3PR	2994-3R
5 Metre	2994-5B	2994-5BK	2994-5GY	2994-5PR	2994-5R
8 Metre	2994-8B	2994-8BK	2994-8GY	2994-8PR	2994-8R
10 Metre	2994-10B	2994-10BK	2994-10GY	2994-10PR	2994-10R
15 Metre	2994-15B	2994-15BK	2994-15GY	2994-15PR	2994-15R

# Cat6 Patch Cables

## Slim Cat6 U/UTP LSZH Patch Cables

Part No: 2994 - (Length) + (Colour) see chart

### Part Number Chart

Length	Green 	Pink 	Orange 	White 	Yellow 
0.15 Metre	2994-0.15G	2994-0.15PK	2994-0.15RG	2994-0.15W	2994-0.15Y
0.2 Metre	2994-0.2G	2994-0.2PK	2994-0.2RG	2994-0.2W	2994-0.2Y
0.3 Metre	2994-0.3G	2994-0.3PK	2994-0.3RG	2994-0.3W	2994-0.3Y
0.5 Metre	2994-0.5G	2994-0.5PK	2994-0.5RG	2994-0.5W	2994-0.5Y
0.75 Metre	2994-0.75G	2994-0.75PK	2994-0.75RG	2994-0.75W	2994-0.75Y
1 Metre	2994-1G	2994-1PK	2994-1RG	2994-1W	2994-1Y
1.5 Metre	2994-1.5G	2994-1.5PK	2994-1.5RG	2994-1.5W	2994-1.5Y
2 Metre	2994-2G	2994-2PK	2994-2RG	2994-2W	2994-2Y
3 Metre	2994-3G	2994-3PK	2994-3RG	2994-3W	2994-3Y
5 Metre	2994-5G	2994-5PK	2994-5RG	2994-5W	2994-5Y
8 Metre	2994-8G	2994-8PK	2994-8RG	2994-8W	2994-8Y
10 Metre	2994-10G	2994-10PK	2994-10RG	2994-10W	2994-10Y
15 Metre	2994-15G	2994-15PK	2994-15RG	2994-15W	2994-15Y