


# Intashield IS-400

## 4 PORT RS232

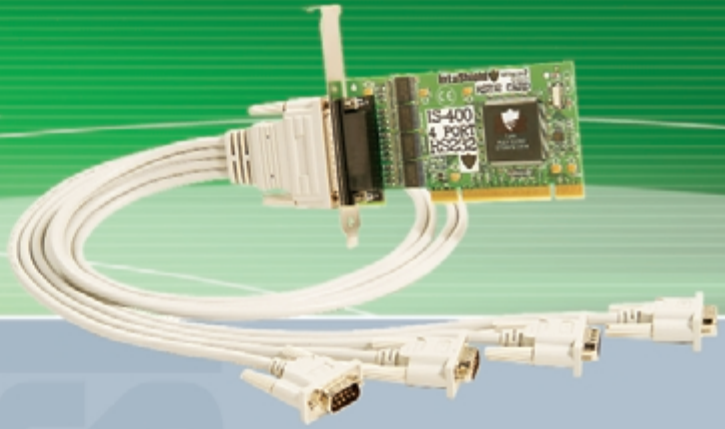

### ■ PRODUCT INFORMATION

#### ■ OPERATING SYSTEMS:

Windows 2000, Windows XP,  
Windows Server 2003


#### ■ PRODUCT FEATURES:

- 4x9 pin, D type RS232 Serial Ports on adaptor cable
- PCI Bus - Fully Plug & Play
- PCI 2.3 Compliant
- 16 Byte transmit and receive FIFO
- Supports both 3.3V / 5V standards
- Drivers for all popular operating systems
- Test software provided
- Install guide, FAQ and other support documents provided

#### ■ SPECIFICATIONS:

- Serial Ports: 4 x RS232
- Adaptor Cable: 44 Way D Female to 4 x 9 Way D Male
- UART: 16550
- Speed: 115,200 maximum baud rate
- Data Bits: 5, 6, 7 or 8
- Stop Bits: 1 or 2
- Parity: Odd, even, none, mark or space
- FIFO Size: 16 byte
- Bus type: 32-bit PCI
- IRQs: Plug and play - Shared interrupts for all ports

- This card provides 4 industry standard RS232 serial COM ports in a single PCI slot. A fully moulded quad cable terminated in 9 pin male D plug ensures a reliable connection. As PCI is fully Plug & Play compatible the operating system or BIOS automatically configures the card ensuring conflict free installation.

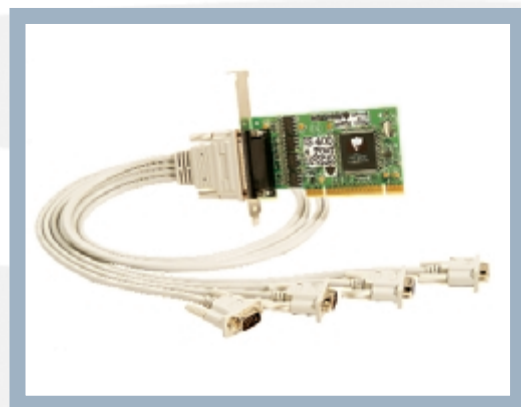

- **INTASHIELD IS-400 4 PORT RS232**  
PRODUCT CODE: IS-400 Version 2