


3m (10ft) Laptop Power Cord, EU Schuko to C5, 2.5A 250V, 18AWG, Notebook / Laptop Replacement AC Cord, Power Brick Cord, Laptop Charger Cable, Clover Leaf/Mickey Mouse Power Cord

Product ID: 753E-3M-POWER-LEAD

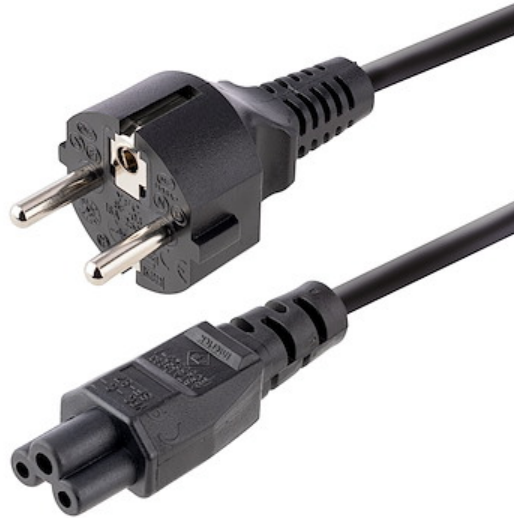

The 753E-3M-POWER-LEAD 3m Laptop Power Cord features one Schuko CEE 7 European power plug and one 3-prong IEC 60320 C5 connector. It is a suitable replacement cable for an HP, Toshiba or other compatible laptop equipped with a C6 enabled power brick.

This product is backed for life, including free lifetime 24/5 multi-lingual technical assistance.

Certifications, Reports and Compatibility



Applications

Features

- **AC POWER CABLE:** This 3m (9.8ft) 18AWG (0.75mm) flexible laptop power cord with an EU Schuko Plug and an IEC 60320 C5 connectors is suitable for power bricks featuring a C6 inlet. Workstation/home office use. Rated to carry 250V at 2.5A.
- **PERFORMANCE AND SAFETY:** Fully molded strain reliefs for durability. VDE approved cable. Fire Rating: VW-1. Jacket Rating: H03VV-F 3 Conductor Notebook Power Cable made with 100% copper wire.
- **SPECS:** 3m (9.8ft) Power Cable. EU Schuko Plug to IEC 60320 C5. 18AWG (0.75mm). 250V 2.5A (Max). Jacket

Material: PVC Jacket Dimensions: 6mm (0.24in) Color: Black Temperature Range: -10 to 35 (14 to 95F)

- **COMPATIBILITY:** EU Schuko Plug works with European outlets IEC 60320 C5 connector works with C6 inlet power bricks for laptop computers, monitors, scanners, printers, and more Replacement laptop power supply cable/lead

- **THE IT PRO'S CHOICE:** Designed and built for IT Professionals, this laptop charger cord is backed for life, including free lifetime 24/5 multi-lingual technical assistance

Hardware

Warranty	Lifetime
Number of Conductors	3
Connector Plating	Nickel
Cable Jacket Material	PVC - Polyvinyl Chloride
Fire Rating	VW-1 Rated
Cable Type	H03VV-F

Connector(s)

Connector A	1 - CEE 7/7 Power (European)
Connector B	1 - IEC 60320 C5 Power

Power

Input Voltage	250 AC
Input Current	2.5 A

Environmental

Operating Temperature	-10 to 35C (14 to 95F)
Storage Temperature	-15 to 70C (5 to 158F)
Humidity	5%RH ~ 95%RH

Physical Characteristics

Color	Black
Wire Gauge	0.75mm ²
Cable Length	9.8 ft [3 m]
Product Length	1.4 in [3.5 cm]

Product Width	118.1 in [300.0 cm]
Product Height	1.5 in [3.8 cm]
Weight of Product	8.4 oz [238.0 g]

Packaging Information

Package Quantity	1
Package Length	9.7 in [24.6 cm]
Package Width	11.4 in [29.0 cm]
Package Height	1.6 in [4.0 cm]
Shipping (Package) Weight	4.8 oz [135.0 g]

What's in the Box

Included in Package	1 - Laptop Power Cord
---------------------	-----------------------

****Product appearance and specifications are subject to change without notice.***