



<b>EAN:</b>	4013288230041	<b>Size:</b>	0x0x0 mm
<b>Part number:</b>	05006640001	<b>Weight:</b>	0 g
<b>Article number:</b>	Kraftform Kompakt Turbo i 1 Tool Finder	<b>Country of origin:</b>	CZ
		<b>Customs tariff number:</b>	82054000

- 4 times the screwdriving speed thanks to the turbo function (purely mechanical - without battery)
- Activate and deactivate the turbo function by a simple push of a button
- Turbo function especially for smooth couplings
- Can be used without the turbo function like a normal screwdriver for couplings with steadily increasing torque
- Robust, maintenance-free gear made of steel
- VDE blades (157 mm length) with practical spinning function, anti-roll protection and "Take it easy" Tool finder: Colour coding by profile and laser-engraved size indication
- Reduced blade diameter with integrated protective insulation for lower-lying screws
- Individually tested tool as per IEC 60900 at 10,000V

Many users wish to carry out screwdriving operations faster without compromises. With a screwdriver which is precise, allows powerful end screwdriving and is also much faster than a conventional screwdriver. The solution: A planetary drive that can be switched on and off: Integrated in the handle it quadruples the working speed in smooth couplings all mechanically. One hand holds the front part of the handle, the second hand turns the back part of the handle. The turbo function can be switched on and off at the push of a button. Turning it off is recommended for tightening and loosening with high torque as well as for fine adjustments. Robust, maintenance-free steel drive with maximum torque of 14 Nm when the turbo function is deactivated. In the VDE version, the 827 T i Kraftform Turbo bitholding screwdriver with the Wera VDE blades individually tested as per IEC 60900 ensures fast and safe working even under tension (up to 1,000 volt). VDE blades with "Take it easy" Tool finder: Colour coding by profile and laser-engraved size indication - for quick and easy identification of the required tool. In a robust belt pouch. The textile box features a fleece zone at the back. Using the provided self-adhesive hook and loop fastener strips, the textile box can be attached to the Wera 2go components. Or to the wall, shelf or workshop trolley.


**Web link**

Wera - Kraftform Kompakt Turbo i 1 Tool Finder  
05006640001 - 4013288230041

Wera Werkzeuge GmbH  
Korzter Straße 21-25  
D-42349 Wuppertal  
Tel: +49 (0)2 02 / 40 45-0  
E-Mail: info@wera.de



**Faster screwdriving**

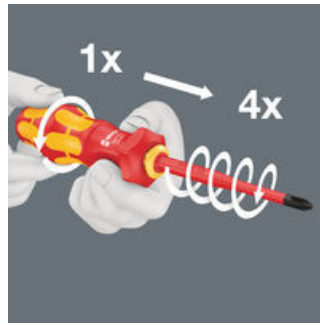


The construction of the Kraftform Turbo allows the speed of manual screwdriving to be quadrupled, especially for smooth couplings - without electricity!

**Robust, maintenance-free gear made of steel**



The robust steel design is maintenance-free and ensures a long product life.

**Handle/interchangeable blade system**

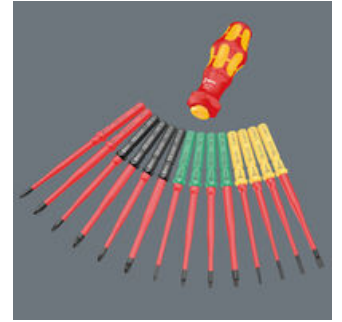

With its 9 mm mounting, the Kraftform Turbo is suitable for all Wera Kraftform Kompakt VDE interchangeable blades. The "holder/interchangeable blade system" stands for flexible working with many screw profiles.

**Individually tested**




The individual testing at 10,000 volts, in accordance with IEC 60900, ensures safe working with loads up to 1,000 volts.

**With and without Turbo**



The turbo function can be switched on or off at the push of a button. Turning it off is recommended for tightening and loosening with high torque as well as for fine adjustments.

**VDE interchangeable blade with reduced shaft diameter**

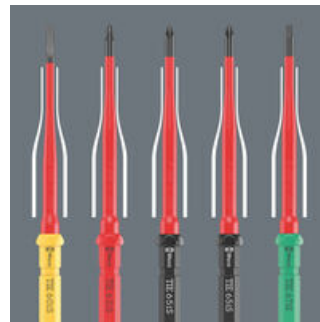

Reduced blade diameter with integrated protective insulation, allows sunken screws and spring elements to be accessed and actuated, individually tested as per IEC 60900.

**PlusMinus screwdrivers**



For the use in terminal blocks, control cabinets, switches, relays, sockets etc.

**Web link**

Wera - Kraftform Kompakt Turbo i 1 Tool Finder  
05006640001 - 4013288230041

Wera Werkzeuge GmbH  
Korzter Straße 21-25  
D-42349 Wuppertal  
Tel: +49 (0)2 02 / 40 45-0  
E-Mail: info@wera.de

Set contents:


**827 T i Kraftform Turbo blade-holding handle, 9 x 125 mm**

05057481001 1x 9 x 125 mm



**817 VDE Kraftform blade-holding handle, 9 x 98 mm**

05003990001 1x 9 x 98 mm

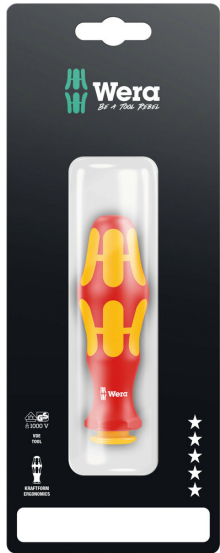

**Kraftform Kompakt VDE 62 iS Take it easy, PH 1 x 157 mm**

1x PH 1 x 157 mm  
1x PH 2 x 157 mm



**Kraftform Kompakt VDE 65 iS Take it easy, PZ 1 x 157 mm**

1x PZ 1 x 157 mm  
1x PZ 2 x 157 mm



**Kraftform Kompakt VDE 65 iS PZ/S Take it easy, # 1 x 157 mm**

1x # 1 x 157 mm  
1x # 2 x 157 mm



**Kraftform Kompakt VDE 67 i TORX® Take it easy, TX 10 x 157 mm**

1x TX 10 x 157 mm



**Kraftform Kompakt VDE 67 iS TORX® Take it easy, TX 15 x 157 mm**

1x TX 15 x 157 mm  
1x TX 20 x 157 mm  
1x TX 25 x 157 mm



**Kraftform Kompakt VDE 60 i Take it easy, 0.4 x 2.5 x 157 mm**

1x 0.4 x 2.5 x 157 mm



Web link

Wera - Kraftform Kompakt Turbo i 1 Tool Finder  
05006640001 - 4013288230041

Wera Werkzeuge GmbH  
Korzter Straße 21-25  
D-42349 Wuppertal  
Tel: +49 (0)2 02 / 40 45-0  
E-Mail: info@wera.de

**Kraftform Kompakt VDE 60 iS Take it easy, 0.6 x 3.5 x 157 mm**



- 1x 0.6 x 3.5 x 157 mm
- 1x 0.8 x 4 x 157 mm
- 1x 1 x 5.5 x 157 mm

**Hook and Loop Fastener Strip 120, 120 x 50 mm**



- 1x 120 x 50 mm

**Web link**

Wera - Kraftform Kompakt Turbo i 1 Tool Finder  
05006640001 - 4013288230041

Wera Werkzeuge GmbH  
Korzter Straße 21-25  
D-42349 Wuppertal  
Tel: +49 (0)2 02 / 40 45-0  
E-Mail: info@wera.de