

# Actuator

46-  
2531.1920.000

Distribution by  
Newark



<https://newark.eao.com/p/46-2531.1920.000>

Your product:

---



## 46-2531.1920.000 Actuator

### FRONT

<b>Front bezel colour:</b>	Yellow
<b>Front bezel material:</b>	Plastic
<b>Front form:</b>	round
<b>Front dimension:</b>	Ø 40 mm

### MOUNTING

<b>Design:</b>	raised
<b>Mounting cut-out:</b>	Ø 22.3 mm

### OPERATING-/INDICATION PART

<b>Lens optics:</b>	opaque
<b>Lens shape:</b>	mushroom-head
<b>Lens illumination:</b>	non illuminative
<b>Lens colour:</b>	Red
<b>Lens material:</b>	Plastic

### ELECTRICAL CHARACTERISTICS

<b>Protection class:</b>	II
--------------------------	----

### MECHANICAL CHARACTERISTIC

<b>Weight:</b>	0.036 kg
<b>Mechanical lifetime:</b>	1 Mio. cycles of operation

**Switching action:** Momentary  
**Tightening torque:** 2 ... 3 Nm (17.7 ... 26.6 Lb-in)

### AMBIENT CONDITION

**Shock resistance:** 30g, 18ms (EN-IEC 60068-2-27)  
50g, 11ms (EN-IEC 60068-2-27)  
**Operating temperature:** - 25 °C ... + 55 °C  
**Climate resistance:** +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)  
**IP front protection:** IP65  
**Vibration resistance:** 5g f= 2...500Hz (EN-IEC 60068-2-6)  
**IK front protection:** IK03


### CERTIFICATE

**Approbations:** CSA, EAC, UL  
**Standards:** CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508  
**Conformities:** CE

### OTHER

**Short Description:** Actuator, Ø 22.3 mm, Ø 40 mm, mushroom-head, non illuminative, Red, Plastic, opaque, round, Yellow, Plastic, Momentary, IP65, IK03

**max. number of switching elements:** 6  
**Housing colour:** Yellow  
**Housing material:** Plastic  
**Mounting cut-outs:**

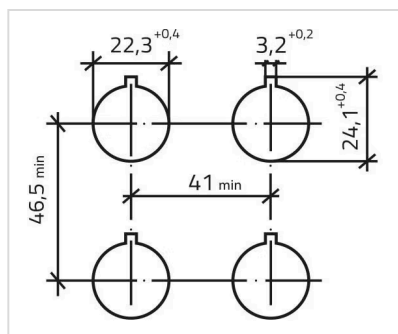

**Dimension drawings:**

