

Actuator

46-

2J31.15T0.000

Distribution by
Newark



<https://newark.eao.com/p/46-2J31.15T0.000>

Your product:

46-2J31.15T0.000

Actuator

Loading ...

FRONT

Front dimension: 58 mm x 29 mm

Front bezel colour: Black

Front bezel material: Plastic

MOUNTING

Design: raised

Mounting cut-out: Ø 22.3 mm

OPERATING-/INDICATION PART

Lens shape: flush

Lens colour: Green-red

Lens material: Plastic

Lens optics: opaque

Lens illumination: non illuminative

ELECTRICAL CHARACTERISTICS

Protection class: II

MECHANICAL CHARACTERISTIC

Mechanical lifetime:	1 Mio. cycles of operation
Weight:	0.025 kg
Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)
Switching action:	Momentary

AMBIENT CONDITION


Climate resistance:	+25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)
Shock resistance:	30g, 18ms (EN-IEC 60068-2-27) 50g, 11ms (EN-IEC 60068-2-27)
IK front protection:	IK03
Operating temperature:	- 25 °C ... + 55 °C
Vibration resistance:	5g f= 2...500Hz (EN-IEC 60068-2-6)
IP front protection:	IP65

CERTIFICATE

Standards:	CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508
Approbations:	CSA, EAC, UL
Conformities:	CE

OTHER

max. number of switching elements:	8
Housing colour:	Black
Housing material:	Plastic
Short Description:	Actuator, Ø 22.3 mm, 58 mm x 29 mm, flush, non illuminative, Green-red, Plastic, opaque, Black, Plastic, Momentary, IP65, IK03
Mounting cut-outs:	

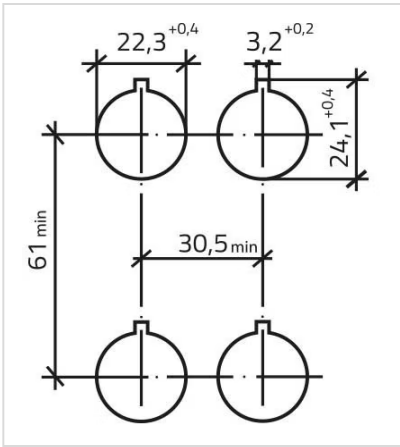

Dimension drawings:

