

Actuator

46-
2Y50.101C.000

Distribution by
Newark



<https://newark.eao.com/p/46-2Y50.101C.000>

Your product:



46-2Y50.101C.000 Actuator

FRONT

Front form:	round
Front bezel colour:	Black
Front dimension:	Ø 29 mm
Front bezel material:	Plastic

MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm

ELECTRICAL CHARACTERISTICS

Electrical lifetime:	>50 000 h
Contact resistance:	<30mOhm
Insulation voltage:	>100MOhm

MECHANICAL CHARACTERISTIC

Tightening torque:	1 ... 2.5 Nm (8.8 ... 22.1 Lb-in)
Terminal:	USB 3.0 socket type C-A
Weight:	0.022 kg
Mechanical lifetime:	>15 000 insertion cycles

AMBIENT CONDITION

IP front protection:	IP20 / IP66 with cap closed (IEC-EN60529)
-----------------------------	---


Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)
Operating temperature: - 25 °C ... + 55 °C
Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
Climate resistance: +40°C-92%RH

CERTIFICATE

Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508
Conformities: CE

OTHER

Housing colour: Black
Short Description: Actuator, Ø 22.3 mm, Ø 29 mm, round, Black, Plastic, USB 3.0 socket type C-A, IP20 / IP66 with cap closed (IEC-EN60529)
Housing material: Plastic
Dimension drawings:

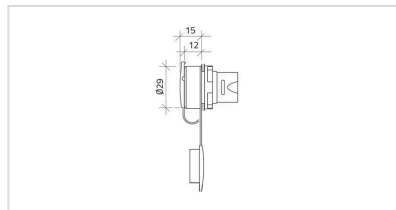

Mounting cut-outs:

