

Actuator

46-
2234.11N0.000

Distribution by
Newark



<https://newark.eao.com/p/46-2234.11N0.000>

Your product:



46-2234.11N0.000 Actuator

FRONT

| | |
|------------------------------|---------|
| Front bezel colour: | Black |
| Front bezel material: | Plastic |
| Front form: | round |
| Front dimension: | Ø 29 mm |

MOUNTING

| | |
|--------------------------|-----------|
| Mounting cut-out: | Ø 22.3 mm |
| Design: | raised |

OPERATING-/INDICATION PART

| | |
|---------------------------|--------------|
| Lens shape: | flush |
| Lens optics: | transparent |
| Lens illumination: | illuminative |
| Lens material: | Plastic |
| Lens colour: | White |

ELECTRICAL CHARACTERISTICS

| | |
|--------------------------|----|
| Protection class: | II |
|--------------------------|----|

MECHANICAL CHARACTERISTIC

| | |
|--------------------------|------------|
| Weight: | 0.019 kg |
| Switching action: | Maintained |

Mechanical lifetime: 500 000 cycles of operation
Tightening torque: 2 ... 3 Nm (17.7 ... 26.6 Lb-in)

AMBIENT CONDITION


IK front protection: IK03
Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)
Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)
Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)
IP front protection: IP65
Operating temperature: - 25 °C ... + 55 °C

CERTIFICATE

Approbations: CSA, EAC, UL
Conformities: CE
Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508

OTHER

Short Description: Actuator, Ø 22.3 mm, Ø 29 mm, flush, illuminative, White, Plastic, transparent, round, Black, Plastic, Maintained, IP65, IK03
Housing material: Plastic
max. number of switching elements: 4
Housing colour: Black
Dimension drawings:

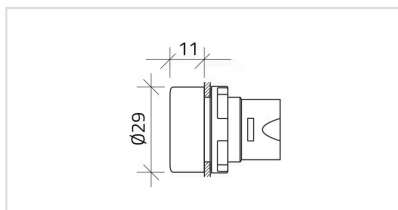

Mounting cut-outs:

