

# Actuator

46-  
2131.1150.000

Distribution by  
Newark



coming soon



<https://newark.eao.com/p/46-2131.1150.000>

Your product:

---

coming soon

# 46-2131.1150.000 Actuator

## FRONT

<b>Front dimension:</b>	Ø 29 mm
<b>Front form:</b>	round
<b>Front bezel material:</b>	Plastic
<b>Front bezel colour:</b>	Black

## MOUNTING

<b>Mounting cut-out:</b>	Ø 22.3 mm
<b>Design:</b>	raised

## OPERATING-/INDICATION PART

<b>Lens optics:</b>	opaque
<b>Lens shape:</b>	flush
<b>Lens colour:</b>	Green
<b>Lens illumination:</b>	non illuminative
<b>Lens material:</b>	Plastic

## ELECTRICAL CHARACTERISTICS

<b>Protection class:</b>	II
--------------------------	----

## MECHANICAL CHARACTERISTIC

<b>Switching action:</b>	Momentary
<b>Tightening torque:</b>	2 ... 3 Nm (17.7 ... 26.6 Lb-in)

**Weight:** 0.019 kg  
**Mechanical lifetime:** 1 Mio. cycles of operation

### AMBIENT CONDITION

**Vibration resistance:** 5g f= 2...500Hz (EN-IEC 60068-2-6)  
**Shock resistance:** 30g, 18ms (EN-IEC 60068-2-27)  
50g, 11ms (EN-IEC 60068-2-27)  
**Operating temperature:** - 25 °C ... + 55 °C  
**Climate resistance:** +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)  
**IK front protection:** IK03  
**IP front protection:** IP65


### CERTIFICATE

**Standards:** CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508  
**Approbations:** CSA, EAC, UL  
**Conformities:** CE

### OTHER

**Short Description:** Actuator, Ø 22.3 mm, Ø 29 mm, flush, non illuminative, Green, Plastic, opaque, round, Black, Plastic, Momentary, IP65, IK03

**max. number of switching elements:** 8  
**Housing colour:** Black  
**Housing material:** Plastic  
**Mounting cut-outs:**

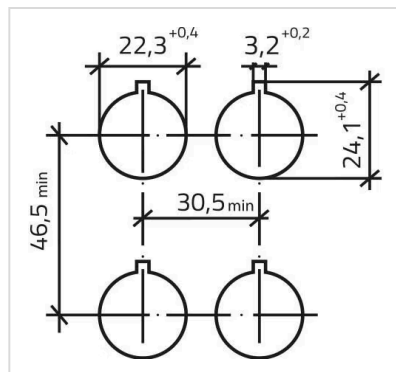

**Dimension drawings:**

