

Actuator

46-
2234.11J0.000

Distribution by
Newark



<https://newark.eao.com/p/46-2234.11J0.000>

Your product:



46-2234.11J0.000 Actuator

FRONT

Front bezel material: Plastic

Front dimension: Ø 29 mm

Front form: round

Front bezel colour: Black

MOUNTING

Design: raised

Mounting cut-out: Ø 22.3 mm

OPERATING-/INDICATION PART

Lens shape: flush

Lens illumination: illuminative

Lens optics: transparent

Lens material: Plastic

Lens colour: Blue

ELECTRICAL CHARACTERISTICS

Protection class: II

MECHANICAL CHARACTERISTIC

Switching action: Maintained

Weight: 0.019 kg

Mechanical lifetime: 500 000 cycles of operation
Tightening torque: 2 ... 3 Nm (17.7 ... 26.6 Lb-in)

AMBIENT CONDITION


Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)
Operating temperature: - 25 °C ... + 55 °C
Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)
IP front protection: IP65
Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)
IK front protection: IK03

CERTIFICATE

Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508
Conformities: CE
Approbations: CSA, EAC, UL

OTHER

Housing colour: Black
max. number of switching elements: 4
Short Description: Actuator, Ø 22.3 mm, Ø 29 mm, flush, illuminative, Blue, Plastic, transparent, round, Black, Plastic, Maintained, IP65, IK03
Housing material: Plastic
Dimension drawings:

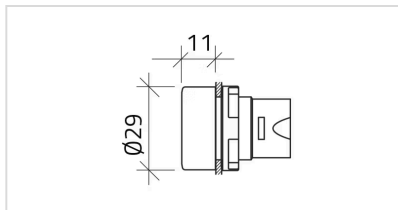

Mounting cut-outs:

