

# Actuator

46-  
2736.1910.000

Distribution by  
Newark



coming soon



<https://newark.eao.com/p/46-2736.1910.000>

Your product:

---

coming soon

## 46-2736.1910.000 Actuator

### FRONT

<b>Front bezel colour:</b>	Yellow
<b>Front bezel material:</b>	Plastic
<b>Front form:</b>	round
<b>Front dimension:</b>	Ø 40 mm

### MOUNTING

<b>Mounting cut-out:</b>	Ø 22.3 mm
<b>Design:</b>	raised

### OPERATING-/INDICATION PART

<b>Lens material:</b>	Plastic
<b>Lens optics:</b>	opaque
<b>Lens illumination:</b>	non illuminative
<b>Lens colour:</b>	Black
<b>Lens shape:</b>	mushroom-head

### ELECTRICAL CHARACTERISTICS

<b>Protection class:</b>	II
--------------------------	----

### MECHANICAL CHARACTERISTIC

<b>Tightening torque:</b>	2 ... 3 Nm (17.7 ... 26.6 Lb-in)
<b>Mechanical lifetime:</b>	50 000 cycles of operation

**Weight:** 0.036 kg  
**Release type:** Twist to unlock

### AMBIENT CONDITION


**IK front protection:** IK03  
**Operating temperature:** - 25 °C ... + 55 °C  
**Climate resistance:** +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)  
**Vibration resistance:** 5g f= 2...500Hz (EN-IEC 60068-2-6)  
**Shock resistance:** 30g, 18ms (EN-IEC 60068-2-27)  
50g, 11ms (EN-IEC 60068-2-27)  
**IP front protection:** IP65

### CERTIFICATE

**Standards:** CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, IEC EN 60947-5-5, UL508, UNI EN ISO 12100, UNI EN ISO 13850  
**Conformities:** CE  
**Approbations:** CSA, EAC, UL

### OTHER

**Dimension:** Ø 40 mm  
**Housing material:** Plastic  
**Short Description:** Actuator, Ø 22.3 mm, Ø 40 mm, mushroom-head, non illuminative, Black, Plastic, opaque, round, Yellow, Plastic, IP65, IK03, Twist to unlock  
**max. number of switching elements:** 4  
**Housing colour:** Yellow  
**Mounting cut-outs:**

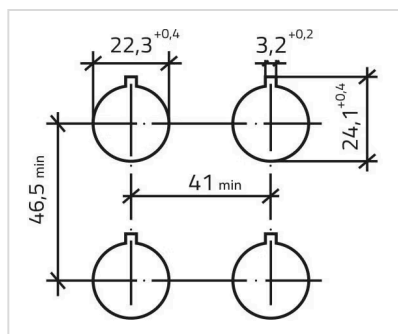

**Dimension drawings:**

