

# Actuator

46-  
2W44.3CZ0.001

Distribution by  
Newark



<https://newark.eao.com/p/46-2W44.3CZ0.001>

Your product:

---



## 46-2W44.3CZ0.001 Actuator

### FRONT

<b>Front bezel material:</b>	Metal
<b>Front bezel colour:</b>	Silver
<b>Front form:</b>	round
<b>Front dimension:</b>	Ø 30 mm

### MOUNTING

<b>Design:</b>	raised
<b>Mounting cut-out:</b>	Ø 22.3 mm

### OPERATING-/INDICATION PART

<b>Lever bar colour:</b>	Black
<b>Lever shape:</b>	short
<b>Lever colour:</b>	Yellow
<b>Lever material:</b>	plastic

### ELECTRICAL CHARACTERISTICS

<b>Protection class:</b>	II
--------------------------	----

### MECHANICAL CHARACTERISTIC

<b>Switching action:</b>	Maintained - Momentary
<b>Mechanical lifetime:</b>	1 Mio. cycles of operation
<b>Switching angle:</b>	90°

**Switching positions:** 2 positions  
**Tightening torque:** 2 ... 3 Nm (17.7 ... 26.6 Lb-in)  
**Weight:** 0.038 kg

#### AMBIENT CONDITION

**Shock resistance:** 30g, 18ms (EN-IEC 60068-2-27)  
50g, 11ms (EN-IEC 60068-2-27)  
**IK front protection:** IK03  
**Operating temperature:** - 25 °C ... + 55 °C  
**Vibration resistance:** 5g f= 2...500Hz (EN-IEC 60068-2-6)  
**IP front protection:** IP65  
**Climate resistance:** +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

#### CERTIFICATE

**Standards:** CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508  
**Conformities:** CE

#### OTHER


**Short Description:** Actuator, Ø 22.3 mm, Ø 30 mm, illuminative, Yellow, short, round, Silver, Metal, Maintained - Momentary, IP65, IK03

**max. number of switching elements:** 2

**Housing material:** Plastic

**Housing colour:** Black

**Switching positions:**

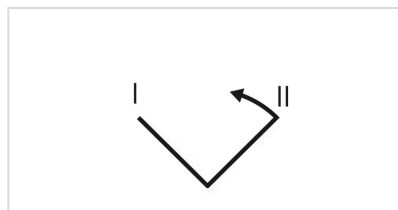

**Dimension drawings:**

