

Actuator

46-
2W44.3CM0.001

Distribution by
Newark



<https://newark.eao.com/p/46-2W44.3CM0.001>

Your product:



46-2W44.3CM0.001 Actuator

FRONT

| | |
|------------------------------|---------|
| Front form: | round |
| Front bezel colour: | Silver |
| Front dimension: | Ø 30 mm |
| Front bezel material: | Metal |

MOUNTING

| | |
|--------------------------|-----------|
| Design: | raised |
| Mounting cut-out: | Ø 22.3 mm |

OPERATING-/INDICATION PART

| | |
|--------------------------|---------|
| Lever colour: | Green |
| Lever shape: | short |
| Lever material: | plastic |
| Lever bar colour: | White |

ELECTRICAL CHARACTERISTICS

| | |
|--------------------------|----|
| Protection class: | II |
|--------------------------|----|

MECHANICAL CHARACTERISTIC

| | |
|-----------------------------|----------------------------------|
| Tightening torque: | 2 ... 3 Nm (17.7 ... 26.6 Lb-in) |
| Switching positions: | 2 positions |
| Switching angle: | 90° |

Mechanical lifetime: 1 Mio. cycles of operation
Switching action: Maintained - Momentary
Weight: 0.038 kg

AMBIENT CONDITION

IP front protection: IP65
Operating temperature: - 25 °C ... + 55 °C
Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)
Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)
IK front protection: IK03
Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

CERTIFICATE

Conformities: CE
Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508

OTHER


Short Description: Actuator, Ø 22.3 mm, Ø 30 mm, illuminative, Green, short, round, Silver, Metal, Maintained - Momentary, IP65, IK03

max. number of switching elements: 2

Housing material: Plastic

Housing colour: Black

Dimension drawings:

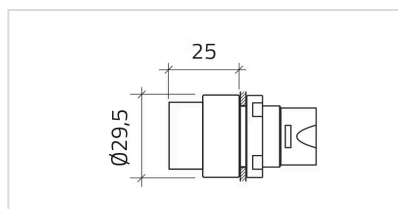

Switching positions:

