

Actuator

46-
2K31.15T0.000

Distribution by
Newark



coming soon



<https://newark.eao.com/p/46-2K31.15T0.000>

Your product:

coming soon

46-2K31.15T0.000 Actuator

FRONT

Front bezel colour:	Black
Front dimension:	58 mm x 29 mm
Front bezel material:	Plastic

MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm

OPERATING-/INDICATION PART

Lens illumination:	illuminative
Lens shape:	flush
Lens colour:	Green-red
Lens optics:	opaque
Lens material:	Plastic

ELECTRICAL CHARACTERISTICS

Protection class:	II
--------------------------	----

MECHANICAL CHARACTERISTIC

Weight:	0.025 kg
Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)
Switching action:	Momentary

Mechanical lifetime: 1 Mio. cycles of operation

AMBIENT CONDITION

Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)

Operating temperature: - 25 °C ... + 55 °C

IP front protection: IP65

Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)

IK front protection: IK03

CERTIFICATE

Conformities: CE

Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508

Approbations: CSA, EAC, UL

OTHER


Housing colour: Black

Housing material: Plastic

Short Description: Actuator, Ø 22.3 mm, 58 mm x 29 mm, flush, illuminative, Green-red, Plastic, opaque, Black, Plastic, Momentary, IP65, IK03

max. number of switching elements: 8

Dimension drawings:

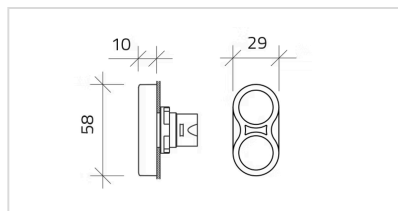

Mounting cut-outs:

