

Actuator

46-
2W0S.1CN0.004

Distribution by
Newark



<https://newark.eao.com/p/46-2W0S.1CN0.004>

Your product:



46-2W0S.1CN0.004 Actuator

FRONT

Front bezel material:	Plastic
Front bezel colour:	Black
Front form:	round
Front dimension:	Ø 30 mm

MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm

OPERATING-/INDICATION PART

Lever bar colour:	White
Lever shape:	short
Lever colour:	White
Lever material:	plastic

ELECTRICAL CHARACTERISTICS

Protection class:	II
--------------------------	----

MECHANICAL CHARACTERISTIC

Switching action:	Momentary - Rest - Momentary
Mechanical lifetime:	1 Mio. cycles of operation
Switching angle:	45° left / 45° right

Weight: 0.027 kg
Tightening torque: 2 ... 3 Nm (17.7 ... 26.6 Lb-in)
Switching positions: 3 positions

AMBIENT CONDITION


IK front protection: IK03
Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)
Operating temperature: - 25 °C ... + 55 °C
Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)
IP front protection: IP65

CERTIFICATE


Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508
Conformities: CE

OTHER

Short Description: Actuator, Ø 22.3 mm, Ø 30 mm, illuminative, White, short, round, Black, Plastic, Momentary - Rest - Momentary, IP65, IK03
Housing material: Plastic
Housing colour: Black
max. number of switching elements: 2
Dimension drawings:

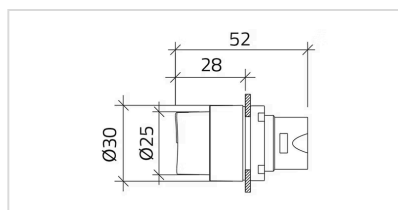

Switching positions:

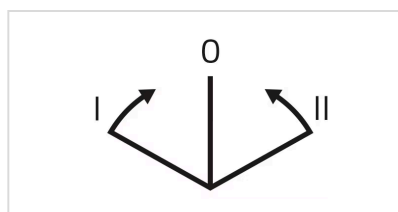

Mounting cut-outs:

