

Actuator

46-
2Y49.101C.000

Distribution by
Newark



<https://newark.eao.com/p/46-2Y49.101C.000>

Your product:



46-2Y49.101C.000 Actuator

FRONT

| | |
|------------------------------|---------|
| Front bezel material: | Plastic |
| Front dimension: | Ø 29 mm |
| Front form: | round |
| Front bezel colour: | Black |

MOUNTING

| | |
|--------------------------|-----------|
| Mounting cut-out: | Ø 22.3 mm |
| Design: | raised |

ELECTRICAL CHARACTERISTICS

| | |
|-----------------------------|-----------|
| Contact resistance: | <30mOhm |
| Insulation voltage: | >100MOhm |
| Electrical lifetime: | >50 000 h |

MECHANICAL CHARACTERISTIC

| | |
|-----------------------------|-----------------------------------|
| Terminal: | USB 3.0 socket type A-A |
| Weight: | 0.024 kg |
| Mechanical lifetime: | >15 000 insertion cycles |
| Tightening torque: | 1 ... 2.5 Nm (8.8 ... 22.1 Lb-in) |

AMBIENT CONDITION

| | |
|-------------------------------|---------------------|
| Operating temperature: | - 25 °C ... + 55 °C |
|-------------------------------|---------------------|

IP front protection: IP20 / IP66 with cap closed (IEC-EN60529)

Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)

Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)

Climate resistance: +40°C-92%RH

CERTIFICATE

Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508, USB 3.0 type A

Conformities: CE


OTHER

Short Description: Actuator, Ø 22.3 mm, Ø 29 mm, round, Black, Plastic, USB 3.0 socket type A-A, IP20 / IP66 with cap closed (IEC-EN60529)

Housing material: Plastic

Housing colour: Black

Dimension drawings:

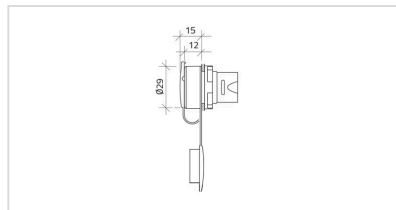

Mounting cut-outs:

