

Actuator

46-
2631.1GE0.000

Distribution by
Newark



<https://newark.eao.com/p/46-2631.1GE0.000>

Your product:



46-2631.1GE0.000 Actuator

FRONT

Front bezel colour:	Black
Front form:	round
Front bezel material:	Plastic
Front dimension:	Ø 38 mm

MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm

OPERATING-/INDICATION PART

Lens shape:	mushroom-head
Lens colour:	Red
Lens optics:	transparent
Lens material:	Plastic
Lens illumination:	illuminative

ELECTRICAL CHARACTERISTICS

Protection class:	II
--------------------------	----

MECHANICAL CHARACTERISTIC

Switching action:	Momentary
Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)

Mechanical lifetime: 1 Mio. cycles of operation

Weight: 0.024 kg

AMBIENT CONDITION

IK front protection: IK03

Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)

Operating temperature: - 25 °C ... + 55 °C

Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)

IP front protection: IP65

CERTIFICATE

Approbations: CSA, EAC, UL

Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508

Conformities: CE

OTHER


max. number of switching elements: 8

Housing material: Plastic

Short Description: Actuator, Ø 22.3 mm, Ø 38 mm, mushroom-head, illuminative, Red, Plastic, transparent, round, Black, Plastic, Momentary, IP65, IK03

Housing colour: Black

Dimension drawings:

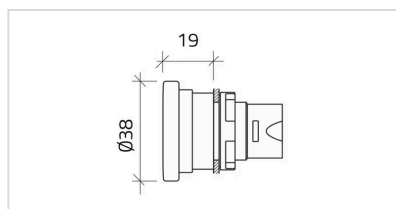

Mounting cut-outs:

