

Actuator

46-
2737.1920.000



<https://eao.com/p/46-2737.1920.000>

Your product:



46-2737.1920.000 Actuator

FRONT

Front bezel colour:	Yellow
Front bezel material:	Plastic
Front dimension:	Ø 40 mm
Front form:	round

MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm

OPERATING-/INDICATION PART

Lens illumination:	non illuminative
Lens shape:	mushroom-head
Lens material:	Plastic
Lens colour:	Red
Lens optics:	opaque

ELECTRICAL CHARACTERISTICS

Protection class:	II
--------------------------	----

MECHANICAL CHARACTERISTIC

Release type:	Pull unlock
Weight:	0.036 kg

Mechanical lifetime: 50 000 cycles of operation
Tightening torque: 2 ... 3 Nm (17.7 ... 26.6 Lb-in)

AMBIENT CONDITION

IK front protection: IK03
IP front protection: IP65
Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)
Operating temperature: - 25 °C ... + 55 °C
Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)
Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)


CERTIFICATE

Conformities: CE
Approbations: CSA, EAC, UL
Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, IEC EN 60947-5-5, UL508, UNI EN ISO 12100, UNI EN ISO 13850

OTHER

Dimension: Ø 40 mm
Housing colour: Yellow
max. number of switching elements: 4
Housing material: Plastic
Short Description: Actuator, Ø 22.3 mm, Ø 40 mm, mushroom-head, non illuminative, Red, Plastic, opaque, round, Yellow, Plastic, IP65, IK03, Pull unlock

Dimension drawings:

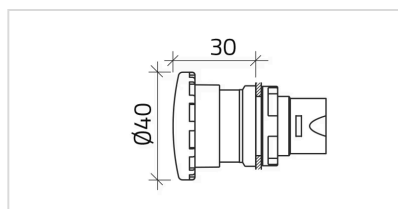

Mounting cut-outs:

