

Actuator

46-
2134.1110.000

Distribution by
Newark



<https://newark.eao.com/p/46-2134.1110.000>

Your product:



46-2134.1110.000 Actuator

FRONT

Front bezel colour:	Black
Front bezel material:	Plastic
Front dimension:	Ø 29 mm
Front form:	round

MOUNTING

Mounting cut-out:	Ø 22.3 mm
Design:	raised

OPERATING-/INDICATION PART

Lens shape:	flush
Lens colour:	Black
Lens illumination:	non illuminative
Lens material:	Plastic
Lens optics:	opaque

ELECTRICAL CHARACTERISTICS

Protection class:	II
--------------------------	----

MECHANICAL CHARACTERISTIC

Mechanical lifetime:	500 000 cycles of operation
Switching action:	Maintained

Weight: 0.019 kg
Tightening torque: 2 ... 3 Nm (17.7 ... 26.6 Lb-in)

AMBIENT CONDITION


IK front protection: IK03
Operating temperature: - 25 °C ... + 55 °C
Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)
IP front protection: IP65
Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)
Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)

CERTIFICATE

Approbations: CSA, EAC, UL
Conformities: CE
Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508

OTHER

max. number of switching elements: 4
Housing material: Plastic
Housing colour: Black
Short Description: Actuator, Ø 22.3 mm, Ø 29 mm, flush, non illuminative, Black, Plastic, opaque, round, Black, Plastic, Maintained, IP65, IK03
Mounting cut-outs:

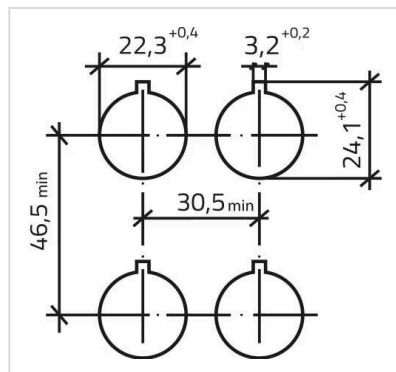

Dimension drawings:

