

Actuator

46-
2828.3CP0.001

Distribution by
Farnell



<https://farnell.eao.com/p/46-2828.3CP0.001>

Your product:



46-2828.3CP0.001 Actuator

FRONT

Front form:	round
Front bezel material:	Metal
Front dimension:	Ø 30 mm
Front bezel colour:	Silver

MOUNTING

Mounting cut-out:	Ø 22.3 mm
Design:	raised

OPERATING-/INDICATION PART

Lever shape:	short
Lever colour:	Red
Lever bar colour:	White
Lever material:	plastic

ELECTRICAL CHARACTERISTICS

Protection class:	II
--------------------------	----

MECHANICAL CHARACTERISTIC

Mechanical lifetime:	1 Mio. cycles of operation
Switching action:	Maintained - Maintained
Weight:	0.038 kg

Switching angle: 90°
Tightening torque: 2 ... 3 Nm (17.7 ... 26.6 Lb-in)
Switching positions: 2 positions

AMBIENT CONDITION


Operating temperature: - 25 °C ... + 55 °C
Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)
Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)
IP front protection: IP65
IK front protection: IK03
Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)

CERTIFICATE

Conformities: CE
Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508

OTHER

Housing colour: Black
max. number of switching elements: 4
Housing material: Plastic
Short Description: Actuator, Ø 22.3 mm, Ø 30 mm, non illuminative, Red, short, round, Silver, Metal, Maintained - Maintained, IP65, IK03
Switching positions:

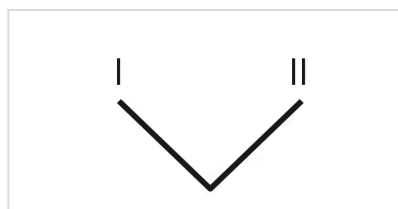

Dimension drawings:

