

# Actuator

46-  
290K.1000.7P8

Distribution by  
Farnell



<https://farnell.eao.com/p/46-290K.1000.7P8>

Your product:

---



## 46-290K.1000.7P8 Actuator

### FRONT

<b>Front dimension:</b>	Ø 29 mm
<b>Front bezel colour:</b>	Black
<b>Front bezel material:</b>	Plastic
<b>Front form:</b>	round

### MOUNTING

<b>Mounting cut-out:</b>	Ø 22.3 mm
<b>Design:</b>	raised

### ELECTRICAL CHARACTERISTICS

<b>Protection class:</b>	II
--------------------------	----

### MECHANICAL CHARACTERISTIC

<b>Switching positions:</b>	2 positions
<b>Weight:</b>	0.076 kg
<b>Mechanical lifetime:</b>	50 000 cycles of operation
<b>Tightening torque:</b>	2 ... 3 Nm (17.7 ... 26.6 Lb-in)
<b>Switching angle:</b>	60° right
<b>Switching action:</b>	Rest (a) - Momentary

### AMBIENT CONDITION

<b>Shock resistance:</b>	30g, 18ms (EN-IEC 60068-2-27) 50g, 11ms (EN-IEC 60068-2-27)
--------------------------	--

**IP front protection:** IP65

**Vibration resistance:** 5g f= 2...500Hz (EN-IEC 60068-2-6)

**Climate resistance:** +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

**Operating temperature:** - 25 °C ... + 55 °C

**IK front protection:** IK06

**CERTIFICATE**

**Approbations:** CSA, EAC, UL

**Standards:** CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508

**Conformities:** CE

**OTHER**


**Short Description:** Actuator, Ø 22.3 mm, Ø 29 mm, round, Black, Plastic, Rest (a) - Momentary, IP65, IK06

**Housing material:** Plastic


**max. number of switching elements:** 8

**Housing colour:** Black

**Dimension drawings:**

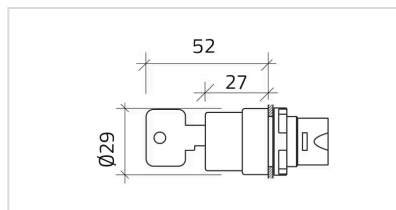

**Mounting cut-outs:**

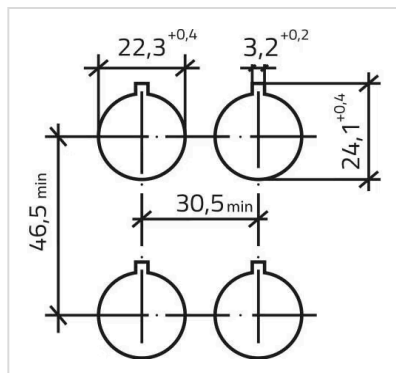

**Switching positions:**

