

Actuator

46-
2W28.3CP0.001

Distribution by
Farnell



<https://farnell.eao.com/p/46-2W28.3CP0.001>

Your product:



46-2W28.3CP0.001 Actuator

FRONT

Front form: round

Front dimension: Ø 30 mm

Front bezel colour: Silver

Front bezel material: Metal

MOUNTING

Design: raised

Mounting cut-out: Ø 22.3 mm

OPERATING-/INDICATION PART

Lever material: plastic

Lever shape: short

Lever bar colour: White

Lever colour: Red

ELECTRICAL CHARACTERISTICS

Protection class: II

MECHANICAL CHARACTERISTIC

Mechanical lifetime: 1 Mio. cycles of operation

Switching positions: 2 positions

Switching action: Maintained - Maintained

Weight: 0.038 kg
Tightening torque: 2 ... 3 Nm (17.7 ... 26.6 Lb-in)
Switching angle: 90°

AMBIENT CONDITION


Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)
Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)
Operating temperature: - 25 °C ... + 55 °C
Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)
IK front protection: IK03
IP front protection: IP65

CERTIFICATE

Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508
Conformities: CE

OTHER

Short Description: Actuator, Ø 22.3 mm, Ø 30 mm, illuminative, Red, short, round, Silver, Metal, Maintained - Maintained, IP65, IK03
Housing material: Plastic
Housing colour: Black
max. number of switching elements: 2
Dimension drawings:

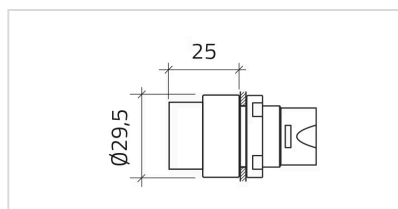

Switching positions:

