


**Pressure Switch - 77039 (//sensing.honeywell.com/product-page?pr\_id=)**

( Home (/) : Products (/products) : Switches : Pressure and Vacuum Switches : Pressure Switch : 5000 )

Distributor Inventory

Input part number for stock availability

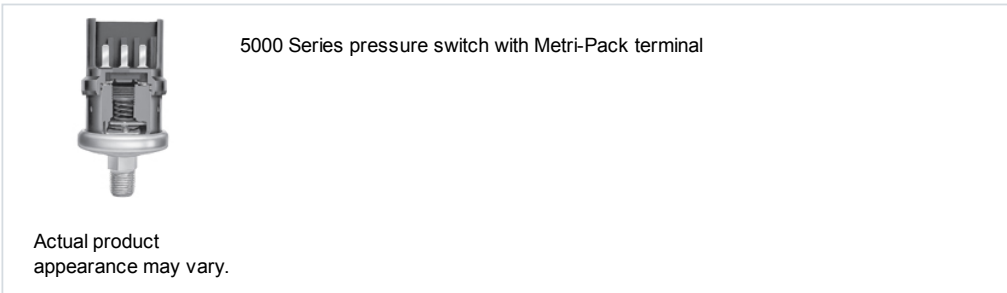

[Sales & Service](#)

[Distributor Inventory](#)

[Overview](#)

[Specs](#)

[Documentation](#)

**Product Specifications**

Product Type	Pressure Switch
Electrical Termination	280 Series Metri-Pack mates with Packard 15300027
Contact Setting Range	4 psi to 6 psi, ±1 psi
Standard Factory Set Points	4 psi, 5 psi & 6 psi
Circuitry	SPDT circuit, one circuit adjustable
Contact(s)	Silver alloy, gold plated
Proof Pressure	500 psi
Burst Pressure	750 psi
Operating Pressure	250 psi
Resistive Ratings	15 A, 6 Vdc; 8 A, 12 Vdc; 4 A, 24 Vdc
Inductive Ratings	1 A, 120 Vac; 0.5 A, 240 Vac
Standard Seal	Nitrile O-ring
Diaphragm	Polymide film
Temperature	-40 °F to 250 °F
Base	Plated steel
Cover Type	Glass reinforced polyester
Options	Brass, plastic, or stainless steel base; various base connector thread sizes; wire leads (potted and sealed)
Connector(s)	1/8-27 NPT male thread
Availability	Global
Series Name	5000

**Narrow Your Search**

**Modify Your Search**

**Products**

Select Option

**Technology**

Select Option

**Industries Served**

Select Option

**Product Search**

Product Type:

Industry:

New Products Only

Entire Product Catalog

Search Term:

**Search**

### My Links


[eCOM Login \(/index.php?ci\\_id=50629&la\\_id=1\)](#)  
[Request Access to eCOM \(/ecom-access-request\)](#)  
[Rep/AD Portal Login \(/index.php?ci\\_id=50606&la\\_id=1\)](#)  
[Rep/AD Portal Access Request \(/index.php?ci\\_id=50630&la\\_id=1\)](#)  
[Sample Request \(/samplerequest\)](#)  
[Digital U - HWL Learning Hub Login \(/index.php?ci\\_id=50607&la\\_id=1\)](#)  
[Limitless Microsite \(/index.php?ci\\_id=50631&la\\_id=1\)](#)  
[Supplier Microsite \(/index.php?ci\\_id=44887&la\\_id=1\)](#)  
[\(\[/contact\]\(#\)\)](#)  
[\(\[/contact\]\(#\)\)](#)

### Literature and Media

[Data Sheets \(/white-paper-and-technical-data-sheets-library2\)](#)  
[Videos \(/videos\)](#)  
[Literature \(/literature\)](#)  
[Literature Request \(/index.php?ci\\_id=50636&la\\_id=1\)](#)  
[White Papers \(/whitepapers\)](#)  
[Application Notes \(/application-notes\)](#)  
[Application Demos \(/index.php?ci\\_id=141383&la\\_id=1\)](#)  
[CAD Renderings \(/cad-renderings\)](#)

### Contacts

[Customer Service \(/index.php?ci\\_id=50608&la\\_id=1\)](#)  
[Technical Support \(/index.php?ci\\_id=50609&la\\_id=1\)](#)  
[Global Sales & Service \(/index.php?ci\\_id=50610&la\\_id=1\)](#)

 [\(/www.youtube.com/user/SensingAndControl\)](#)

[Terms & Conditions \(/terms & conditions\)](#)

[Privacy Statement \(/index.php?ci\\_id=2589&la\\_id=1\)](#)

[\(\[/contact\]\(#\)\)](#)  
**CHAT**  
[\(\[/contact\]\(#\)\)](#)

[Sitemap](#)