

CD-HF 25X25 - Cable duct

3240340

<https://www.phoenixcontact.com/in/products/3240340>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cable duct for installation and mounting in control cabinets, light gray, halogen-free, comprising upper part and mounting base, width: 25 mm, height: 25 mm, length: 2000 mm

Your advantages

- Predetermined breaking point enables tool-free, burr-free removal of bars
- Thanks to its leverage and special cutting geometry, the PPS CD cable duct cutter enables easy, burr-free cutting with minimum effort
- Easy, burr-free cutting with minimum effort using the CUTFOX-CD cable duct cutter
- The wide, diagonal heads of the cable duct bars make it easy to fit the cover and hold it securely in place
- Installed conductors are securely held in place by means of wire retaining clips that can be snapped onto bars on the side
- Plastic body-bound rivets enable easy fixing of cable ducts using the rivet setting tool
- Fast and seamless creation of T and cross connections by means of an additional predetermined breaking point in the cable duct base

Commercial data

Item number	3240340
Packing unit	25 pc
Minimum order quantity	25 pc
Sales key	BE7
Product key	BE7441
Catalog page	Page 579 (C-3-2019)
GTIN	4046356507257
Weight per piece (including packing)	480 g
Weight per piece (excluding packing)	480 g
Customs tariff number	39259020
Country of origin	DE

CD-HF 25X25 - Cable duct

3240340

<https://www.phoenixcontact.com/in/products/3240340>



Technical data


Product properties

Product type	Wiring duct
--------------	-------------

Connection data

Nominal cross section	220 mm ²
-----------------------	---------------------

Dimensions

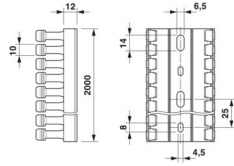Dimensional drawing	
Width	25 mm
Height	2000 mm
Depth	25 mm
Length	2000 mm

Material specifications

Color	light grey RAL 7035
Material	PC/ABS
Flammability rating according to UL 94	V0
Fire protection for rail vehicles (DIN EN 45545-2) R22	HL 1 - HL 3
Fire protection for rail vehicles (DIN EN 45545-2) R23	HL 1 - HL 3
Components	halogen-free

Cable/line

Halogen-free	yes
--------------	-----

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-40 °C ... 90 °C
---------------------------------	------------------

CD-HF 25X25 - Cable duct


3240340

<https://www.phoenixcontact.com/in/products/3240340>



Drawings

Dimensional drawing

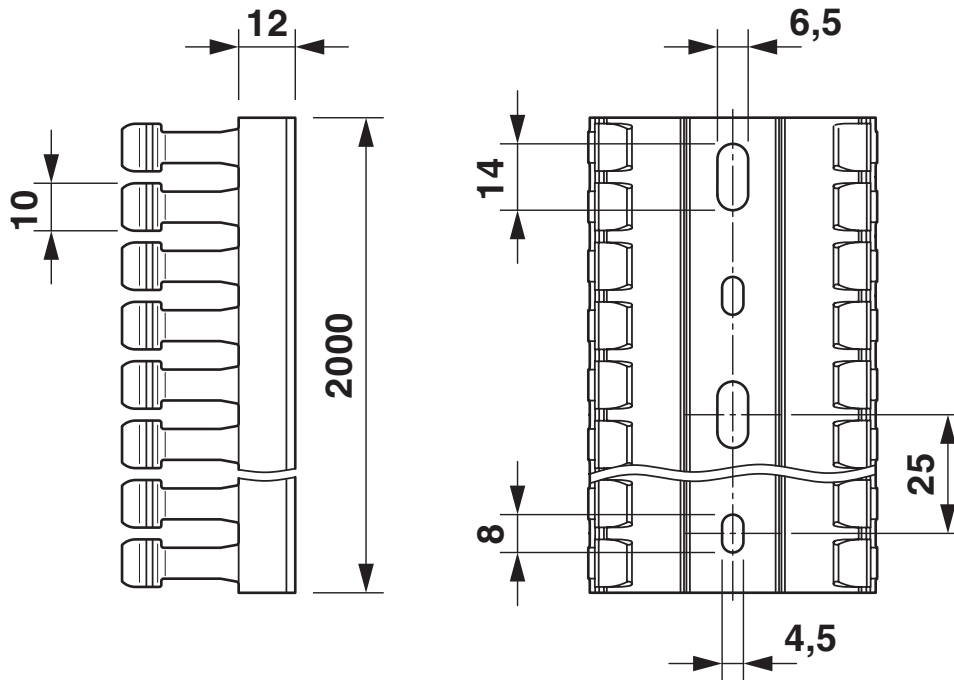

Base perforation according to DIN EN 50085

CD-HF 25X25 - Cable duct



3240340

<https://www.phoenixcontact.com/in/products/3240340>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/3240340>



CSA

Approval ID: 248269



UL Recognized

Approval ID: FILE E 328576



VDE Zeichengenehmigung

Approval ID: 40028972

DNV

Approval ID: TAE00004VN

CD-HF 25X25 - Cable duct

3240340

<https://www.phoenixcontact.com/in/products/3240340>



Classifications

ECLASS

ECLASS-11.0	27400703
ECLASS-12.0	27400703
ECLASS-13.0	27400703

ETIM

ETIM 9.0	EC000012
----------	----------

UNSPSC

UNSPSC 21.0	39131700
-------------	----------

CD-HF 25X25 - Cable duct

3240340

<https://www.phoenixcontact.com/in/products/3240340>



Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

CD-HF 25X25 - Cable duct

3240340

<https://www.phoenixcontact.com/in/products/3240340>



Accessories

CD-HF COVER 25 - Cover profile

3240369

<https://www.phoenixcontact.com/in/products/3240369>



Cover for cable duct, light gray, halogen-free, width: 25 mm, length: 2000 mm

RVT-PA 4 - Fastening clip

3240498

<https://www.phoenixcontact.com/in/products/3240498>



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

CD-HF 25X25 - Cable duct

3240340

<https://www.phoenixcontact.com/in/products/3240340>



RVT-PA 6 - Fastening clip

3240499

<https://www.phoenixcontact.com/in/products/3240499>



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

UNIFOX-RVT P 4 - Tool

1212478

<https://www.phoenixcontact.com/in/products/1212478>



Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets

CD-HF 25X25 - Cable duct

3240340

<https://www.phoenixcontact.com/in/products/3240340>



UNIFOX-RVT P 6 - Tool

1212509

<https://www.phoenixcontact.com/in/products/1212509>

Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets



Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in