

# CD-HF 40X40 - Cable duct

3240348

<https://www.phoenixcontact.com/in/products/3240348>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cable duct for installation and mounting in control cabinets, light gray, halogen-free, comprising upper part and mounting base, width: 40 mm, height: 40 mm, length: 2000 mm

## Your advantages

- Predetermined breaking point enables tool-free, burr-free removal of bars
- Thanks to its leverage and special cutting geometry, the PPS CD cable duct cutter enables easy, burr-free cutting with minimum effort
- Easy, burr-free cutting with minimum effort using the CUTFOX-CD cable duct cutter
- The wide, diagonal heads of the cable duct bars make it easy to fit the cover and hold it securely in place
- Installed conductors are securely held in place by means of wire retaining clips that can be snapped onto bars on the side
- Plastic body-bound rivets enable easy fixing of cable ducts using the rivet setting tool

## Commercial data

Item number	3240348
Packing unit	25 pc
Minimum order quantity	25 pc
Sales key	BE7
Product key	BE7441
Catalog page	Page 579 (C-3-2019)
GTIN	4046356508339
Weight per piece (including packing)	606 g
Weight per piece (excluding packing)	606 g
Customs tariff number	39259020
Country of origin	DE

# CD-HF 40X40 - Cable duct

3240348

<https://www.phoenixcontact.com/in/products/3240348>



## Technical data


### Product properties

Product type	Wiring duct
--------------	-------------

### Connection data

Nominal cross section	749 mm <sup>2</sup>
-----------------------	---------------------

### Dimensions

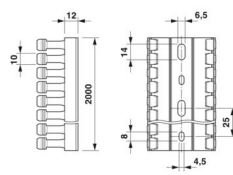Dimensional drawing	
Width	40 mm
Height	2000 mm
Depth	40 mm
Length	2000 mm

### Material specifications

Color	light grey RAL 7035
Material	PC/ABS
Flammability rating according to UL 94	V0
Components	halogen-free

### Cable/line

Halogen-free	yes
--------------	-----

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 90 °C
---------------------------------	------------------

# CD-HF 40X40 - Cable duct


3240348

<https://www.phoenixcontact.com/in/products/3240348>



## Drawings

Dimensional drawing

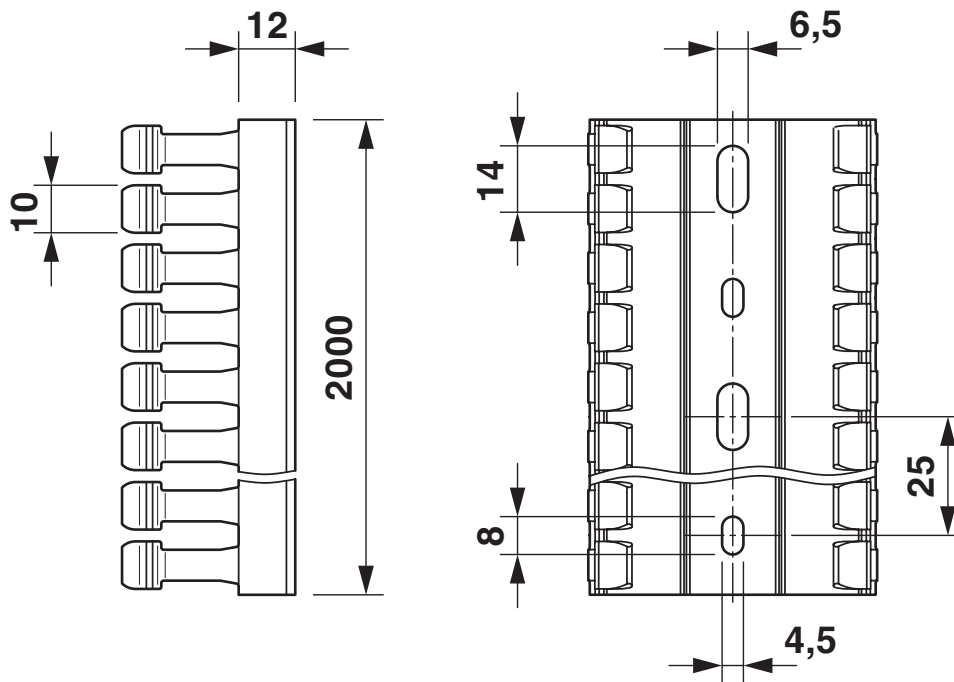

Base perforation according to DIN EN 50085

# CD-HF 40X40 - Cable duct



3240348

<https://www.phoenixcontact.com/in/products/3240348>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/3240348>



**CSA**

Approval ID: 248269



**UL Recognized**

Approval ID: FILE E 328576



**VDE Zeichengenehmigung**

Approval ID: 40028972



**EAC**

Approval ID: RU C-DE.PB68.W.00513

**DNV**

Approval ID: TAE00004VN

# CD-HF 40X40 - Cable duct

3240348

<https://www.phoenixcontact.com/in/products/3240348>



## Classifications

### ECLASS

ECLASS-11.0	27400703
ECLASS-12.0	27400703
ECLASS-13.0	27400703

### ETIM

ETIM 9.0	EC000012
----------	----------

### UNSPSC

UNSPSC 21.0	39131700
-------------	----------

# CD-HF 40X40 - Cable duct

3240348

<https://www.phoenixcontact.com/in/products/3240348>



## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

# CD-HF 40X40 - Cable duct

3240348

<https://www.phoenixcontact.com/in/products/3240348>



## Accessories

### CD-HF COVER 40 - Cover profile

3240371

<https://www.phoenixcontact.com/in/products/3240371>



Cover for cable duct, light gray, halogen-free, width: 40 mm, length: 2000 mm

---

### RVT-PA 4 - Fastening clip

3240498

<https://www.phoenixcontact.com/in/products/3240498>



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

## CD-HF 40X40 - Cable duct

3240348

<https://www.phoenixcontact.com/in/products/3240348>



## RVT-PA 6 - Fastening clip

3240499

<https://www.phoenixcontact.com/in/products/3240499>



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

---

## UNIFOX-RVT P 4 - Tool

1212478

<https://www.phoenixcontact.com/in/products/1212478>



Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets



# CD-HF 40X40 - Cable duct

3240348

<https://www.phoenixcontact.com/in/products/3240348>



## UNIFOX-RVT P 6 - Tool

1212509

<https://www.phoenixcontact.com/in/products/1212509>

Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets



---

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

[info@phoenixcontact.co.in](mailto:info@phoenixcontact.co.in)