




Produktname | *Product name*: Battery Tester  
 Artikelnummer | *Part Number*: 400001-03  
 Anfragenummer | *Inquiry Number*: AN20602N  
 Ersteller / Datum | *Creator / Date*: ka / 2023-02-28

Version	Änderung / Change	Datum / Date	Name
V05	Minimum cell voltage added	2023-07-13	ka
V04	Changed to new datasheet format	2023-02-28	ka

Template name: ANSMANN xxxx-xxxx\_0DA, Template version: V50

Zeichnung des Testgerätes / Drawing of the test device:

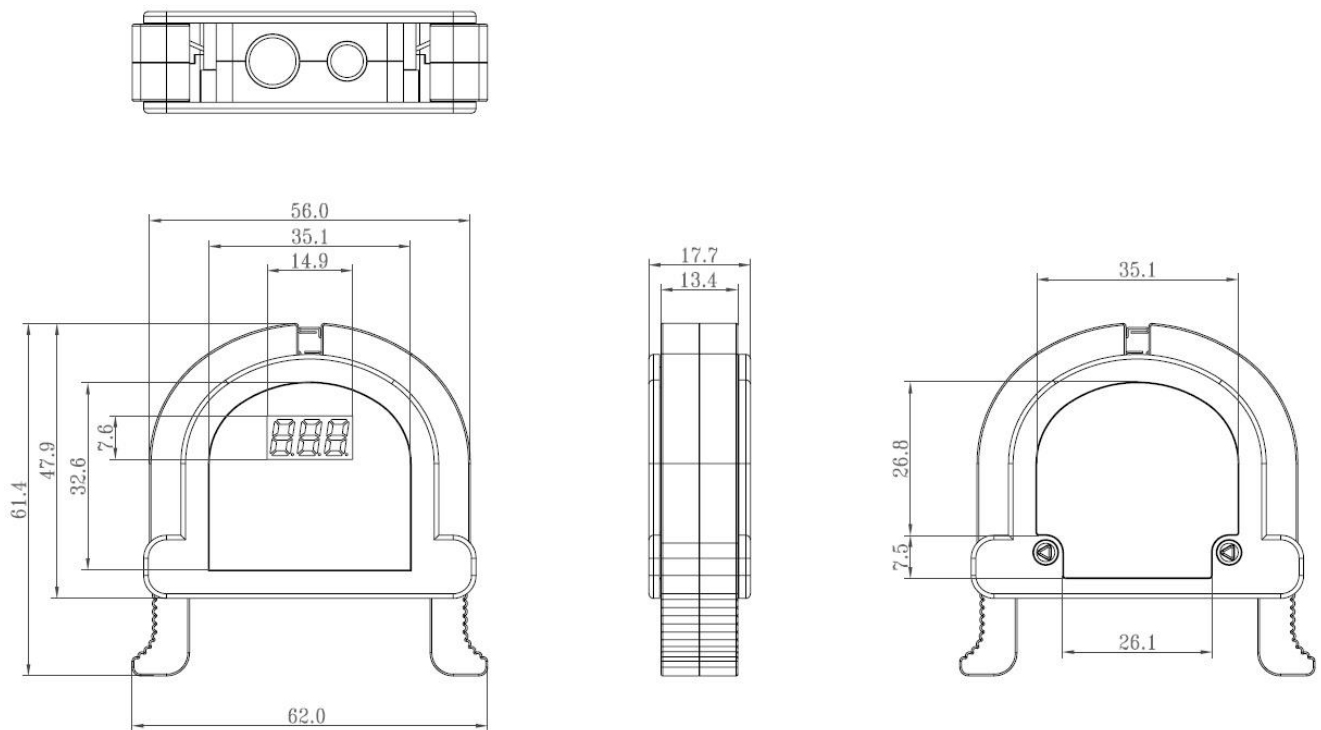

Allowable deviation / general tolerances DIN ISO 2768-c

**Technische Daten des Testgerätes / Technical data of the test device:**



**Elektrische Daten:**

**Electrical data:**

Mindeste Zellspannung für eine Anzeige:	Rundzellen: 0,9V 9V E-Block: 4,2V	Minimum cell voltage for a indication:	Cylindrical cells: 0.9V 9V E-Block: 4.2V
---	--------------------------------------	--	---

**Allgemeine Daten:**

**Common data:**

LCD Anzeige:	Batteriespannung (in V)	LCD indicator:	Battery voltage (in V)
Approbationen:	CE	Approvals:	CE
Gewicht:	31 g	Weight:	31 g
Lieferumfang:	- Testgerät	Shipment:	- Test device
Verpackung:	Farbige Faltschachtel	Package:	Coloured folding box

**Testfunktion für diese Zellen / Test function for these cells:**

Standard Alkaline Batterien / standard Alkaline batteries:

1,5V Rundzellen / cylindric cells:  
AAA, AA, C, D

9V:  
9V-E-Block

Aufladbare Batterien / rechargeable batteries:

1,2V NiCd / NiMH:  
AAA, AA, C, D

9V:  
9V-E-Block