




S410



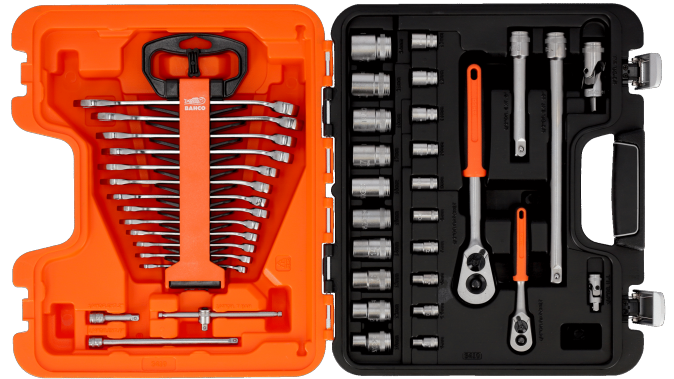

1/4" and 1/2" Square Drive Socket Set with Metric Hex Profile and Combination Spanner Set



PRODUCT DETAILS

- 10-piece 1/4" hex socket set: 5, 5.5, 6, 7, 8, 9, 10, 11, 12 and 13 mm
- 2-piece 1/4" extension bars, 50 mm/2" and 150 mm/6"
- 1-piece 1/4" sliding T-bar: 100 mm/4"
- 1-piece 1/4" universal joint
- 1-piece 1/4" ratchet, quick-release, 60 teeth/6° action angle
- 10-piece 1/2" hex sockets 10, 12, 13, 14, 15, 16, 17, 19, 21 and 24 mm
- 2-piece 1/2" extension bars, 125 mm/5" and 250 mm/10"
- 1-piece 1/2" universal joint
- 1-piece 1/2" ratchet: quick-release, 60 teeth/6° action angle
- 12-piece combination spanners: 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18 and 19 mm, on a practical removable tool-rack
- Matte finish
- High-performance alloy steel
- Case: high density polythene (HDPE)
- Standards: ISO 1174 and DIN 3120

PRODUCT ATTRIBUTES

Product				
S410	375 mm	320 mm	110 mm	2040 g

Follow the Fish!

