




9031-T

ERGO™ 38 mm Central Nut Wide Opening Thin Jaw Adjustable Wrench with Rubber Handle 218 mm



PRODUCT DETAILS


- Adjustable wrenches developed according to the scientific ERGO™ process
- Maximum comfort with minimum effort thanks to ergonomic design
- Extra-wide jaw opening with a shorter handle than a standard wrench offers accessibility to work in confined spaces
- Up to 60% thinner jaws than standard wrenches of the same size give greater access in tight spaces
- 40% wider opening compared to a standard adjustable wrench
- Jaw will not fall out even at maximum opening of the wrench
- Laser scale in mm for pre-adjusting and accurate measurement
- Skydrol- and oil-resistant rubber handle
- Ergonomically designed thermoplastic elastomer handle distributes pressure uniformly in the hand, reducing the risk for work related injuries
- High-performance alloy steel forged in single piece
- Phosphate finish, precision-hardened and anti-corrosion treated
- Left turning screw
- Standards: ISO 6787, DIN 3117, ASME B107.8 and BS 6333

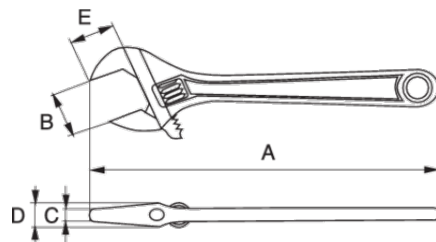

Follow the Fish!



PRODUCT ATTRIBUTES

Product	A	A	B	C	D	E	
9031-T	218 mm	8 in	38 mm	4.5 mm	13.4 mm	34 mm	325 g

