




9033

ERGO™ 46 mm Central Nut Wide Opening Jaw Adjustable Wrench with Rubber Handle and Phosphate Finish 270 mm



PRODUCT DETAILS


- Adjustable wrenches developed according to the scientific ERGO™ process
- Maximum comfort with minimum effort thanks to ergonomic design
- Extra-wide jaw opening with a shorter handle than a standard wrench offers accessibility to work in confined spaces
- Jaw will not fall out even at maximum opening of the wrench
- Head combines slim design for accessibility with strength for performance
- Laser scale in mm for pre-adjusting and accurate measurement
- Skydrol- and oil-resistant rubber handle
- Ergonomically designed thermoplastic elastomer handle distributes pressure uniformly in the hand, reducing the risk for work related injuries
- High-performance alloy steel forged in single piece
- Phosphate, precision-hardened and anti-corrosion treated
- Left turning screw
- Standards: ISO 6787, DIN 3117, ASME B107.8 and BS 6333

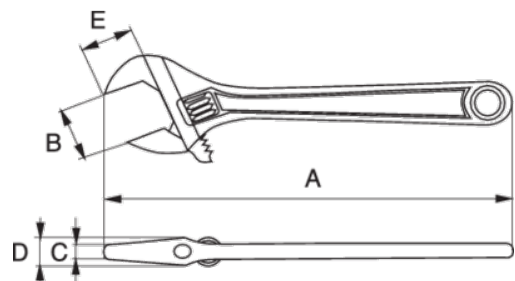

Follow the Fish!



PRODUCT ATTRIBUTES

Product	A	A	B	C	D	E	
9033	270 mm	10 in	46 mm	8 mm	17.8 mm	41 mm	525 g

