


## Category 6/6A UTP 90° UTP Keystone Coupler

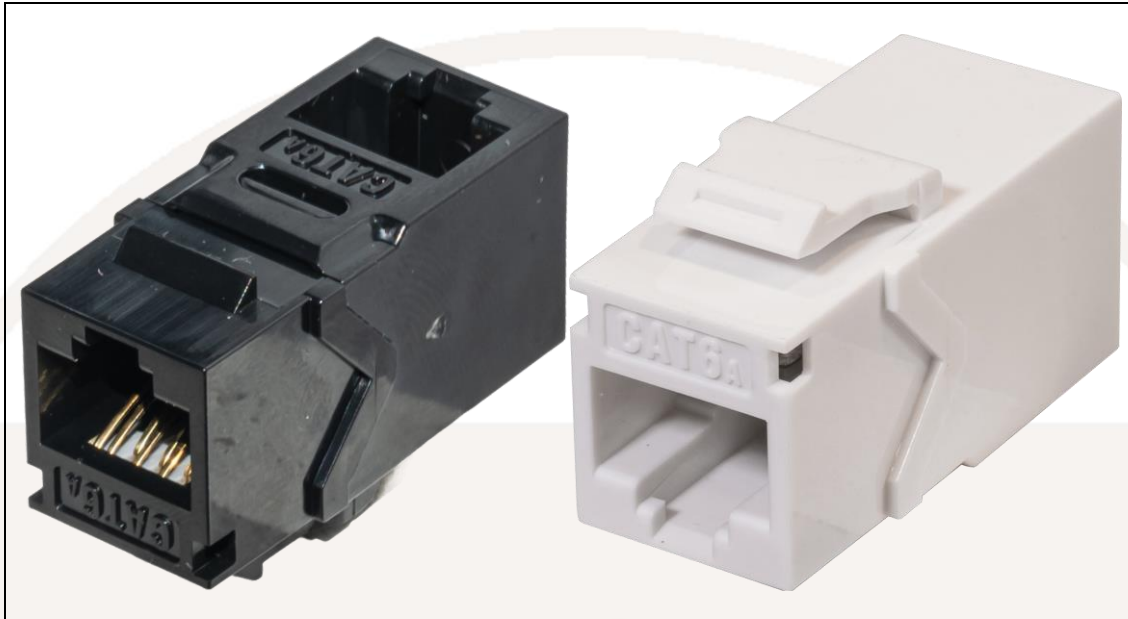

### **90° Keystone Panel Mount Coupler (SGACK90bk/wh)**

High performance coupler ideal for use in backboxes and in limited space.

#### **Features**

- Slim and very compact design enables use in panels or faceplates where width or depth are restricted
- Designed to fit industry standard keystone mount outlets wall plates and patch panels
- High performance data throughput, meets Category 6A UTP data transfer rates
- Compliant with IEEE standard for PoE+ and 4PPoE IEEE 802.3
- High performance alternative to Category 6 UTP, backwards compatible

#### **Specifications**

- Dimensions: 35 x 22.23 x 17mm
- Weight: 8g (including packaging)
- Colour: Black or White
- Materials: Housing: ABS + PCV0  
RJ45 contacts: 50µ"/1.27µm gold plating on phosphor bronze
- Current rating: 1.5A
- Dielectric withstanding voltage: 1000V AC 60Hz
- Insulation resistance: 500MΩ max.
- Contact resistance: 20mΩ min.


**Packaging:** supplied in individual polybags then in bags of 20

**Commodity Code:** 85444920

**EAN:**


SGACK90Bk: 5055386511737  
SGACK90Wh: 5055386511744  
SGACK90Dpm: 5055386511775  
SGACK90Bpm: 5055386511782  
SGACK90Whpm: 5055386511799

**Country of Origin:** China

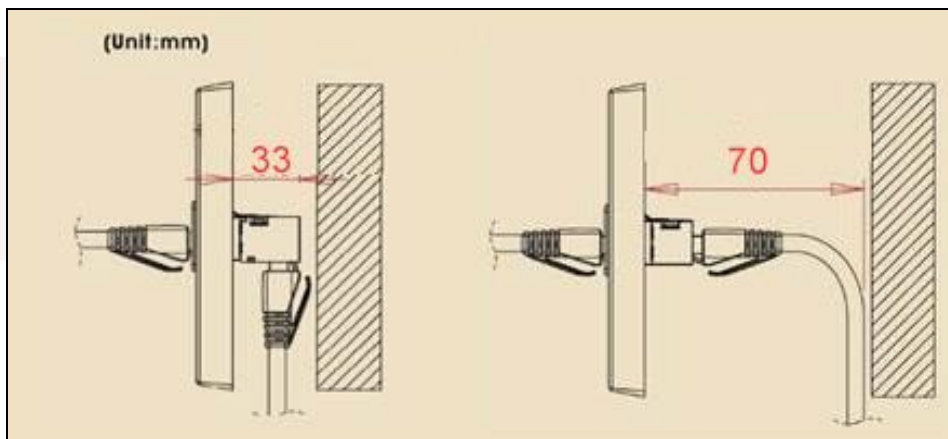

**90° Coupler vs Standard Coupler**

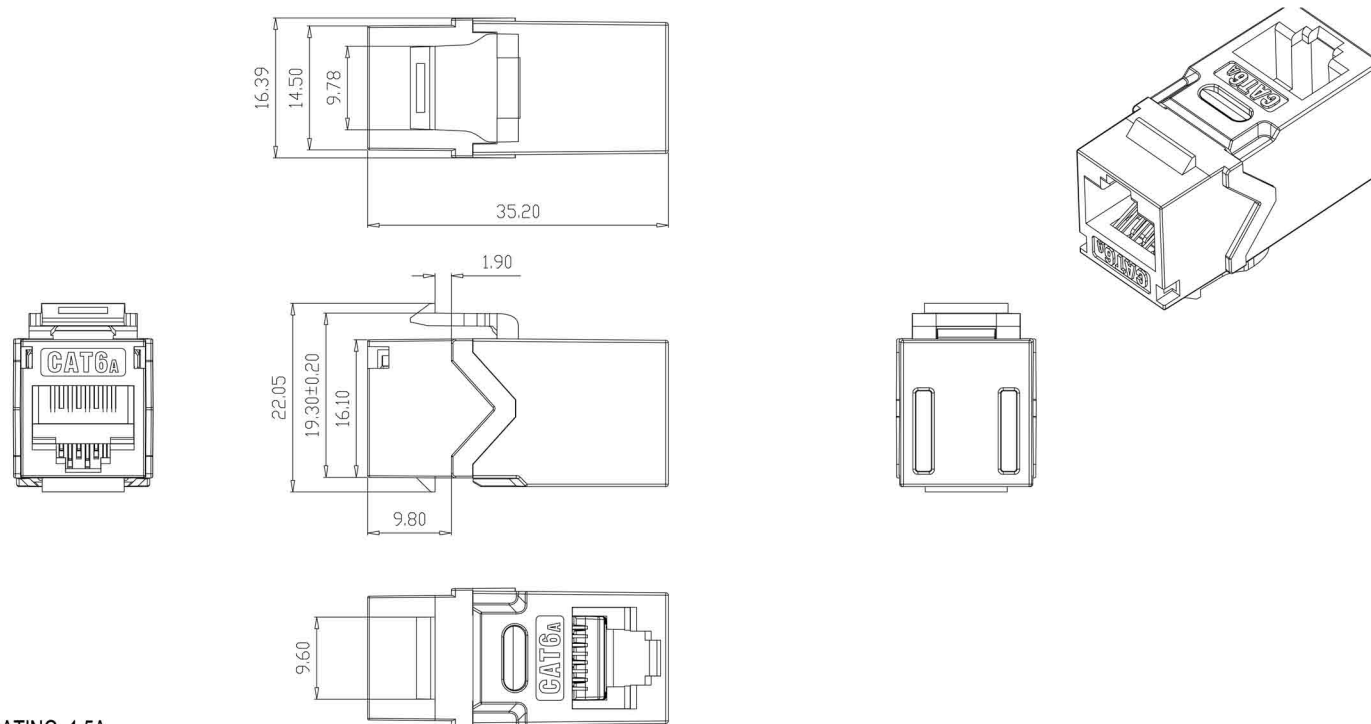

**ELECTRICAL**

CURRENT RATING: 1.5A.  
DIELECTRIC WITHSTANDING VOLTAGE: 1000V AC 60Hz.  
INSULATION RESISTANCE: 500M  $\Omega$  MIN.  
CONTACT RESISTANCE: 20m  $\Omega$  MAX.

**MECHANICAL**

- (1)Materials:ABS+PC V0
- (2)RJ45 Jack Contact:Phosphor bronze,50U"/1.27 $\mu$ m Gold Plating