

RP-TNC Str Jack For 1.13 mm Cable

031-6987


[Find In Stock & Buy Now](#)

RP-TNC Str Jack For 1.13 mm Cable

[+ Add To Parts List](#) [☰ Add To Compare](#)

Product Compliance

- RoHS (EU). Compliant with Exemption 6C - [View Certificate](#)
- California residents see [Prop 65 Warning](#)
- Additional compliance information is available in our [Compliance Center](#).

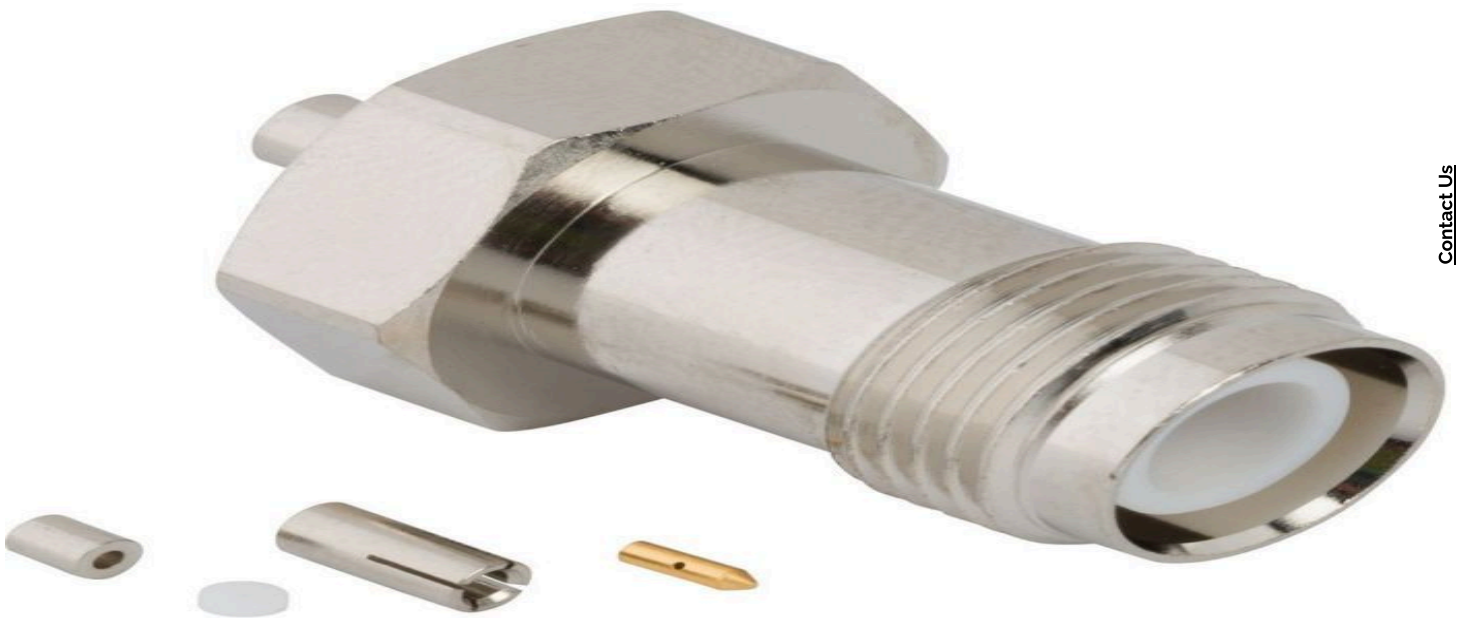

[Contact Us](#)

Description ▼

RP-TNC Str Jack For 1.13 mm Cable

Product Life Cycle

Part Status	Active
--------------------	--------

Product Specifications

Body Finish	Nickel
Body Material	Brass
Cable Type (Terminates to)	1.13 mm Micro-cable
Contact Finish	Gold
Contact Material	Brass
Contact Termination	Solder
Coupling Mechanism	Threaded
Export Control Classification Number	EAR99
Frequency (Max GHz)	6
Gender	Jack

Contact Us

IP Rating	Not Rated
Impedance (Ohms)	50
Insulator Material	PTFE
Isolated	No
Low PIM	No
Mil Qualified	Not Mil Qualified
Non Magnetic	No
Orientation	Straight
Panel Mounting Feature	Not Applicable
Temp (Max Degrees Celsius)	65
Temp (Min Degrees Celsius)	165
Termination Style	Cable - Crimp
Thread Direction	Standard