

Surface-mount Ceramic Multilayer Capacitors (RoHS compliant & Halogen Free)


AC0201000000SB000

AC 0201 ~ 0402 Series Sample Kit

Spec Sheet

Scope

This product specification is applied to Multi-layer Ceramic Capacitor used for Automotive application .

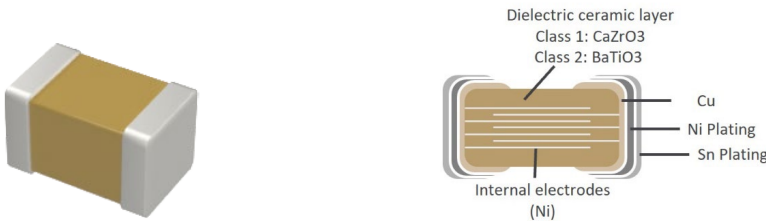

No.	Part NO.	Size	TC	Cap.	Volt.	Tol	No.	Part NO.	Size	TC	Cap.	Volt.	Tol
1	AC0201BRNPO8BN1R0	0201	NPO	1pF	25V	±0.1pF	26	AC0402CRNPO9BN8R2	0402	NPO	8.2pF	50V	±0.25pF
2	AC0201BRNPO8BN1R5	0201	NPO	1.5pF	25V	±0.25pF	27	AC0402JRNPO9BN100	0402	NPO	10pF	50V	±5%
3	AC0201CRNPO8BN2R2	0201	NPO	2.2pF	25V	±0.25pF	28	AC0402JRNPO9BN150	0402	NPO	15pF	50V	±5%
4	AC0201CRNPO8BN3R3	0201	NPO	3.3pF	25V	±0.25pF	29	AC0402JRNPO9BN220	0402	NPO	22pF	50V	±5%
5	AC0201CRNPO8BN4R7	0201	NPO	4.7pF	25V	±0.25pF	30	AC0402JRNPO9BN330	0402	NPO	33pF	50V	±5%
6	AC0201JRNPO8BN100	0201	NPO	10pF	25V	±5%	31	AC0402JRNPO9BN470	0402	NPO	47pF	50V	±5%
7	AC0201JRNPO8BN120	0201	NPO	12pF	25V	±5%	32	AC0402JRNPO9BN101	0402	NPO	100pF	50V	±5%
8	AC0201JRNPO8BN150	0201	NPO	15pF	25V	±5%	33	AC0402JRNPO9BN221	0402	NPO	220pF	50V	±5%
9	AC0201JRNPO8BN180	0201	NPO	18pF	25V	±5%	34	AC0402JRNPO9BN471	0402	NPO	470pF	50V	±5%
10	AC0201JRNPO8BN220	0201	NPO	22pF	25V	±5%	35	AC0402JRNPO9BN102	0402	NPO	1nF	50V	±5%
11	AC0201JRNPO8BN330	0201	NPO	33pF	25V	±5%	36	AC0402KRX7R9BB102	0402	X7R	1nF	50V	±10%
12	AC0201KRX7R8BB101	0201	X7R	100pF	25V	±10%	37	AC0402KRX7R9BB222	0402	X7R	2.2nF	50V	±10%
13	AC0201KRX7R8BB221	0201	X7R	220pF	25V	±10%	38	AC0402KRX7R9BB472	0402	X7R	4.7nF	50V	±10%
14	AC0201KRX7R8BB471	0201	X7R	470pF	25V	±10%	39	AC0402KRX7R9BB103	0402	X7R	10nF	50V	±10%
15	AC0201KRX7R8BB102	0201	X7R	1nF	25V	±10%	40	AC0402KRX7R7BB223	0402	X7R	22nF	16V	±10%
16	AC0201KRX7R8BB222	0201	X7R	2.2nF	25V	±10%	41	AC0402KRX7R7BB333	0402	X7R	33nF	16V	±10%
17	AC0201KRX7R8BB472	0201	X7R	4.7nF	25V	±10%	42	AC0402KRX7R7BB473	0402	X7R	47nF	16V	±10%
18	AC0201KRX7R8BB103	0201	X7R	10nF	25V	±10%	43	AC0402KRX7R7BB104	0402	X7R	100nF	16V	±10%
19	AC0402BRNPO9BN1R0	0402	NPO	1pF	50V	±0.1pF	44	AC0402KRX7R9BB223	0402	X7R	22nF	50V	±10%
20	AC0402BRNPO9BN1R5	0402	NPO	1.5pF	50V	±0.1pF	45	AC0402KRX7R9BB473	0402	X7R	47nF	50V	±10%
21	AC0402CRNPO9BN2R2	0402	NPO	2.2pF	50V	±0.25pF	46	AC0402KRX7R0BB221	0402	X7R	220pF	100V	±10%
22	AC0402CRNPO9BN3R3	0402	NPO	3.3pF	50V	±0.25pF	47	AC0402KRX7R0BB471	0402	X7R	470pF	100V	±10%
23	AC0402CRNPO9BN3R9	0402	NPO	3.9pF	50V	±0.25pF	48	AC0402KRX7R0BB102	0402	X7R	1nF	100V	±10%
24	AC0402CRNPO9BN4R7	0402	NPO	4.7pF	50V	±0.25pF	49	AC0402KRX7R0BB152	0402	X7R	1.5nF	100V	±10%
25	AC0402CRNPO9BN6R8	0402	NPO	6.8pF	50V	±0.25pF							

Piecs per items: Case size 01005 to 0402, 80pcs; 0603 to 1808, 40pcs; 1812, 20pcs.