

SPECIFICATIONS

1. General Specifications


Model	POLE22-0100AT	POLE22-0300AT	POLE22-0500AT	POLE22-0800AT	POLE22-1000AT
Applicable Models	List in the website http://www.patlite.com/				
Applicable Optional Parts					
Mounting Location	Indoor Only				
Mass (Tolerance ±10%)	0.05kg	0.15kg	0.26kg	0.42kg	0.52kg
	(No Accessories)				
Outer Dimensions	Refer to the 3.Outer Dimensions				
Remarks	There are no contents of controlled substances exceeding the threshold for the RoHS				

2. Model Number Configuration

	Model		Pole length	
POLE	POLE22	-	↓	AT
			Pole length	
			0100	100mm
			0300	300mm
			0500	500mm
			0800	800mm
			1000	1000mm

3. Outer Dimensions

POLE22-□AT
(Unit:mm)

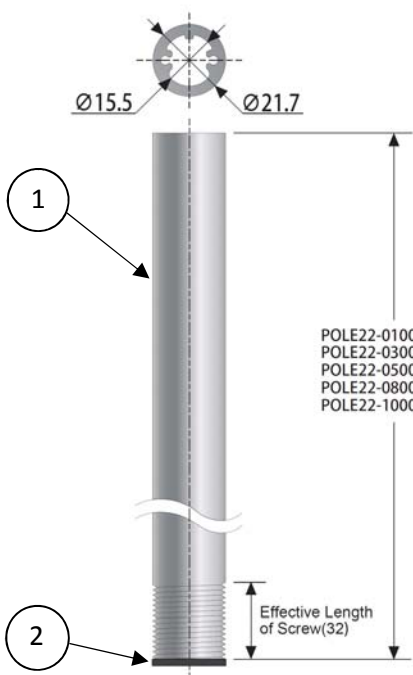

No.	Name	Material
1	Pole	AL
2	Rubber Bushing	EPR

Accessory	
Hexagon Nut(M22) 2pcs.	
Plain Washer(φ 22 Inside Diameter) 2pcs.	
Binding Head Tapping Screw(M3 × 12) 2pcs.	

Color: Silver

POLE22-0300AT-W18C

PATLITE Corporation