



Bud Industries, Inc.

ENCLOSURES RIGHT NOW, RIGHT PRICE

[Check Stock/Pricing by Product No.](#)[Search By Size and Type](#)[Home](#) / [Products](#) / [NEMA / IP Rated Boxes](#) / [NBF Series NEMA Box](#) / NEMA Enclosure Poly PTB Blend NBF-32326

## NEMA Enclosure Poly PTB Blend NBF-32326



2 Videos

### Model # NBF-32326

[NBF Series NEMA Box](#)

- IP65 | IP66
- Designed to IP66 of IEC 529 and NEMA 1, 2, 4 and 4x specifications
- All plastic construction including hinge pins
- Comes complete with stainless steel wall mounting brackets and hardware
- Has two plastic latches
- \*PC/PBT blended plastic enclosures are molded out of light gray material with UL94-5VA flammability rating and UV stabilized

[Check Stock / Pricing](#)[Request Modifications](#)[Compare Sizes and Models](#)[See Accessories](#)**External Size L x W x D:** 15.75" x 11.81" x 6.30"**Internal Size L x W x D:** 14.73" x 10.79" x 5.69"**Weight:** 5.6 lbs**Color:** Light Gray**RoHS Certified:** Always Compliant**Indoor / Outdoor:** Outdoor (UV Stabilized)**Flammability Rating:** UL94-5VA**Door Flammability Rating:** UL94-5VA**Type of Plastic:** Poly PBT Blend

**Door Type of Plastic:** Poly PBT Blend

**UL Rating:** UL508

**Service Temperature Min:** -40°C


**Service Temperature Max:** 75°C

**NEMA Rating:** NEMA 1, NEMA 2, NEMA 4, NEMA 4X

**IP Rating:** IP65, IP66

**Cover Style:** Opaque, Hinged Cover

**DRAWING**

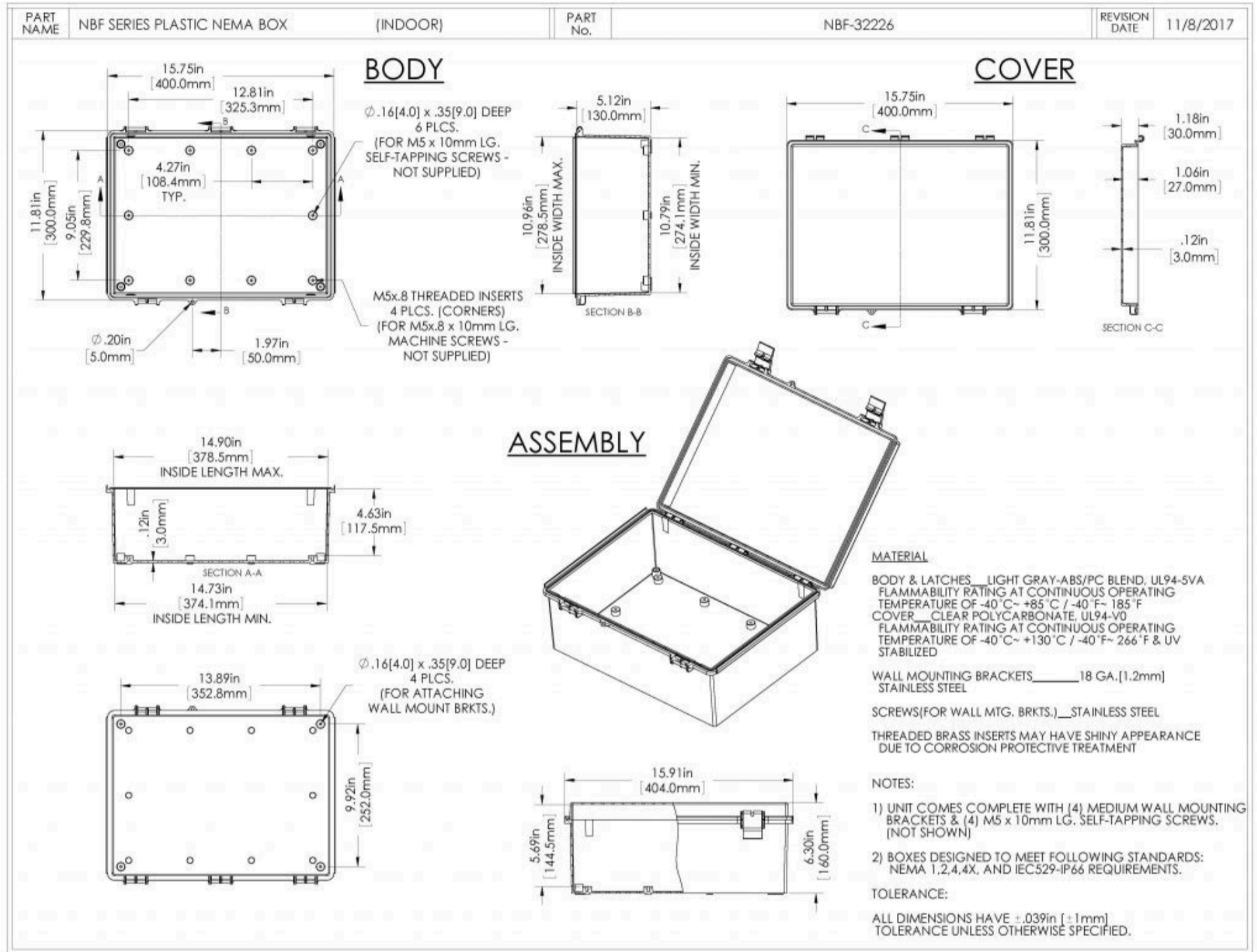

**OTHER MODELS IN THIS SERIES**

-- External Dimensions --  -- Internal Dimensions --  -- Indoor / Outdoor --  -- Type of Plastic --

-- Door Type of Plastic --

Model #	External Dimensions	Internal Dimensions	Indoor / Outdoor	Type of Plastic	Door Type of Plastic
<a href="#">NBF-32202</a>	5.12" x 3.92" x 2.78"	4.37" x 3.11" x 2.27"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32302</a>	5.12" x 3.92" x 2.78"	4.37" x 3.11" x 2.27"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32102</a>	5.12" x 3.92" x 2.78"	4.37" x 3.11" x 2.27"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32002</a>	5.12" x 3.92" x 2.78"	4.37" x 3.11" x 2.27"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32402</a>	5.12" x 3.92" x 2.78"	4.37" x 3.11" x 2.27"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32404</a>	5.90" x 3.92" x 2.78"	5.12" x 3.11" x 2.27"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate


 
 
Model #	External Dimensions	Internal Dimensions	Indoor / Outdoor	Type of Plastic	Door Type of Plastic
<a href="#">NBF-32004</a>	5.90" x 3.92" x 2.78"	5.12" x 3.11" x 2.27"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32304</a>	5.90" x 3.92" x 2.78"	5.12" x 3.11" x 2.27"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32104</a>	5.90" x 3.92" x 2.78"	5.12" x 3.11" x 2.27"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32204</a>	5.90" x 3.92" x 2.78"	5.12" x 3.11" x 2.27"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32110</a>	5.91" x 5.91" x 3.54"	5.26" x 5.26" x 3.03"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32010</a>	5.91" x 5.91" x 3.54"	5.26" x 5.26" x 3.03"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32210</a>	5.91" x 5.91" x 3.54"	5.26" x 5.26" x 3.03"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32310</a>	5.91" x 5.91" x 3.54"	5.26" x 5.26" x 3.03"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32410</a>	5.91" x 5.91" x 3.54"	5.26" x 5.26" x 3.03"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32414</a>	7.72" x 7.72" x 5.71"	6.99" x 6.99" x 5.16"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32114</a>	7.72" x 7.72" x 5.71"	6.99" x 6.99" x 5.16"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32214</a>	7.72" x 7.72" x 5.71"	6.99" x 6.99" x 5.16"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32014</a>	7.72" x 7.72" x 5.71"	6.99" x 6.99" x 5.16"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32314</a>	7.72" x 7.72" x 5.71"	6.99" x 6.99" x 5.16"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32306</a>	7.87" x 3.92" x 2.76"	7.06" x 3.11" x 2.53"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32006</a>	7.87" x 3.92" x 2.76"	7.06" x 3.11" x 2.53"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32206</a>	7.87" x 3.92" x 2.76"	7.06" x 3.11" x 2.53"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32106</a>	7.87" x 3.92" x 2.76"	7.06" x 3.11" x 2.53"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32406</a>	7.87" x 3.92" x 2.76"	7.06" x 3.11" x 2.53"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32412</a>	8.33" x 6.36" x 3.94"	7.50" x 5.55" x 3.35"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32312</a>	8.33" x 6.36" x 3.94"	7.50" x 5.55" x 3.35"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32012</a>	8.33" x 6.36" x 3.94"	7.50" x 5.55" x 3.35"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32212</a>	8.33" x 6.36" x 3.94"	7.50" x 5.55" x 3.35"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32112</a>	8.33" x 6.36" x 3.94"	7.50" x 5.55" x 3.35"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32408</a>	10.63" x 3.92" x 2.76"	9.78" x 3.11" x 2.22"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32208</a>	10.63" x 3.92" x 2.76"	9.78" x 3.11" x 2.22"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32108</a>	10.63" x 3.92" x 2.76"	9.78" x 3.11" x 2.22"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32308</a>	10.63" x 3.92" x 2.76"	9.78" x 3.11" x 2.22"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32008</a>	10.63" x 3.92" x 2.76"	9.78" x 3.11" x 2.22"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32016</a>	11.99" x 7.99" x 5.22"	11.01" x 7.02" x 4.62"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32116</a>	11.99" x 7.99" x 5.22"	11.01" x 7.02" x 4.62"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32216</a>	11.99" x 7.99" x 5.22"	11.01" x 7.02" x 4.62"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32316</a>	11.99" x 7.99" x 5.22"	11.01" x 7.02" x 4.62"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32416</a>	11.99" x 7.99" x 5.22"	11.01" x 7.02" x 4.62"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32418</a>	11.99" x 7.99" x 6.40"	11.02" x 7.02" x 5.81"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32318</a>	11.99" x 7.99" x 6.40"	11.02" x 7.02" x 5.81"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32018</a>	11.99" x 7.99" x 6.40"	11.02" x 7.02" x 5.81"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32118</a>	11.99" x 7.99" x 6.40"	11.02" x 7.02" x 5.81"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32218</a>	11.99" x 7.99" x 6.40"	11.02" x 7.02" x 5.81"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32320</a>	11.99" x 7.99" x 8.01"	11.02" x 7.02" x 7.42"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend



Model #	External Dimensions	Internal Dimensions	Indoor / Outdoor	Type of Plastic	Door Type of Plastic
<a href="#">NBF-32020</a>	11.99" x 7.99" x 8.01"	11.02" x 7.02" x 7.42"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32220</a>	11.99" x 7.99" x 8.01"	11.02" x 7.02" x 7.42"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32120</a>	11.99" x 7.99" x 8.01"	11.02" x 7.02" x 7.42"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32420</a>	11.99" x 7.99" x 8.01"	11.02" x 7.02" x 7.42"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32422</a>	13.78" x 9.84" x 5.91"	12.82" x 8.88" x 5.32"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32322</a>	13.78" x 9.84" x 5.91"	12.82" x 8.88" x 5.32"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32222</a>	13.78" x 9.84" x 5.91"	12.82" x 8.88" x 5.32"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32122</a>	13.78" x 9.84" x 5.91"	12.82" x 8.88" x 5.32"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32022</a>	13.78" x 9.84" x 5.91"	12.82" x 8.88" x 5.32"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32324</a>	13.78" x 9.84" x 7.09"	12.82" x 8.88" x 6.50"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32124</a>	13.78" x 9.84" x 7.09"	12.82" x 8.88" x 6.50"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32024</a>	13.78" x 9.84" x 7.09"	12.82" x 8.88" x 6.50"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32224</a>	13.78" x 9.84" x 7.09"	12.82" x 8.88" x 6.50"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32424</a>	13.78" x 9.84" x 7.09"	12.82" x 8.88" x 6.50"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32426</a>	15.75" x 11.81" x 6.30"	14.73" x 10.79" x 5.69"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32326</a>	15.75" x 11.81" x 6.30"	14.73" x 10.79" x 5.69"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32226</a>	15.75" x 11.81" x 6.30"	14.73" x 10.79" x 5.69"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32126</a>	15.75" x 11.81" x 6.30"	14.73" x 10.79" x 5.69"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32026</a>	15.75" x 11.81" x 6.30"	14.73" x 10.79" x 5.69"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32228</a>	17.72" x 13.78" x 6.42"	16.49" x 12.56" x 5.73"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32028</a>	17.72" x 13.78" x 6.42"	16.49" x 12.56" x 5.73"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32128</a>	17.72" x 13.78" x 6.42"	16.49" x 12.56" x 5.73"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32428</a>	17.72" x 13.78" x 6.42"	16.49" x 12.56" x 5.73"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32328</a>	17.72" x 13.78" x 6.42"	16.49" x 12.56" x 5.73"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32330</a>	17.72" x 13.78" x 7.99"	16.51" x 12.58" x 7.30"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32430</a>	17.72" x 13.78" x 7.99"	16.51" x 12.58" x 5.30"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32230</a>	17.72" x 13.78" x 7.99"	16.49" x 12.56" x 7.30"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32030</a>	17.72" x 13.78" x 7.99"	16.49" x 12.56" x 7.30"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32130</a>	17.72" x 13.78" x 7.99"	16.49" x 12.56" x 7.30"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32032</a>	19.69" x 15.75" x 6.30"	18.68" x 14.74" x 5.65"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32132</a>	19.69" x 15.75" x 6.30"	18.68" x 14.74" x 5.65"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32232</a>	19.69" x 15.75" x 6.30"	18.68" x 14.74" x 5.65"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32432</a>	19.69" x 15.75" x 6.30"	18.68" x 14.74" x 5.65"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32332</a>	19.69" x 15.75" x 6.30"	18.68" x 14.74" x 5.65"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32434</a>	19.69" x 15.75" x 7.87"	18.63" x 14.69" x 7.22"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32334</a>	19.69" x 15.75" x 7.87"	18.63" x 14.69" x 7.22"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32034</a>	19.69" x 15.75" x 7.87"	18.63" x 14.69" x 7.22"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32134</a>	19.69" x 15.75" x 7.87"	18.63" x 14.69" x 7.22"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32234</a>	19.69" x 15.75" x 7.87"	18.63" x 14.69" x 7.22"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32036</a>	20.95" x 17.05" x 6.30"	19.58" x 15.62" x 5.91"	Indoor (Not UV Stabilized)	ABS	ABS

Model #	External Dimensions	Internal Dimensions 	Indoor / Outdoor	Type of Plastic	Door Type of Plastic
<a href="#">NBF-32136</a>	20.95" x 17.05" x 6.30"	19.58" x 15.62" x 5.91"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32236</a>	20.95" x 17.05" x 6.30"	19.58" x 15.62" x 5.91"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32436</a>	20.95" x 17.05" x 6.30"	19.58" x 15.62" x 5.91"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32336</a>	20.95" x 17.05" x 6.30"	19.58" x 15.62" x 5.91"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32438</a>	20.95" x 17.05" x 7.87"	19.58" x 15.62" x 7.17"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32338</a>	20.95" x 17.05" x 7.87"	19.58" x 15.62" x 7.17"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32238</a>	20.95" x 17.05" x 7.87"	19.58" x 15.62" x 7.17"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32138</a>	20.95" x 17.05" x 7.87"	19.58" x 15.62" x 7.17"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32038</a>	20.95" x 17.05" x 7.87"	19.58" x 15.62" x 7.17"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32040</a>	24.96" x 21.02" x 7.09"	23.33" x 19.39" x 6.32"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32140</a>	24.96" x 21.02" x 7.09"	23.33" x 19.39" x 6.32"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32240</a>	24.96" x 21.02" x 7.09"	23.33" x 19.39" x 6.32"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32440</a>	24.96" x 21.02" x 7.09"	23.33" x 19.39" x 6.32"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32340</a>	24.96" x 21.02" x 7.09"	23.33" x 19.39" x 6.32"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32442</a>	24.96" x 21.02" x 9.84"	23.33" x 19.39" x 9.08"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32342</a>	24.96" x 21.02" x 9.84"	23.33" x 19.39" x 9.08"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32142</a>	24.96" x 21.02" x 9.84"	23.33" x 19.39" x 9.08"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32242</a>	24.96" x 21.02" x 9.84"	23.33" x 19.39" x 9.08"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32042</a>	24.96" x 21.02" x 9.84"	23.33" x 19.39" x 9.08"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32146</a>	28.90" x 21.02" x 11.02"	27.22" x 19.34" x 10.28"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32246</a>	28.90" x 21.02" x 11.02"	27.22" x 19.34" x 10.28"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32046</a>	28.90" x 21.02" x 11.02"	27.26" x 19.38" x 9.09"	Indoor (Not UV Stabilized)	ABS	ABS
<a href="#">NBF-32446</a>	28.90" x 21.02" x 11.02"	27.26" x 19.38" x 9.09"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32346</a>	28.90" x 21.02" x 11.02"	27.22" x 19.34" x 10.28"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32444</a>	28.90" x 21.02" x 7.09"	27.36" x 19.48" x 6.34"	Outdoor (UV Stabilized)	Poly PBT Blend	Clear Polycarbonate
<a href="#">NBF-32344</a>	28.90" x 21.02" x 7.09"	27.36" x 19.48" x 6.34"	Outdoor (UV Stabilized)	Poly PBT Blend	Poly PBT Blend
<a href="#">NBF-32144</a>	28.90" x 21.02" x 7.09"	27.36" x 19.48" x 6.34"	Indoor (Not UV Stabilized)	ABS Poly Blend	ABS Poly Blend
<a href="#">NBF-32244</a>	28.90" x 21.02" x 7.09"	27.36" x 19.48" x 6.34"	Indoor (Not UV Stabilized)	ABS Poly Blend	Clear Polycarbonate
<a href="#">NBF-32044</a>	28.90" x 21.02" x 7.09"	27.36" x 19.48" x 6.34"	Indoor (Not UV Stabilized)	ABS	ABS

## ACCESSORIES

 <p><b>Steel Internal Panel 14.25 x 10.43 Inches NBX-32926</b></p>	 <p><b>Plastic Internal Panel 14.25 x 10.43 Inches NBX-32926-PL</b></p>	 <p><b>Locking Hasp NBX-1091</b></p>
---	---	---