

114017-ZZ ✓ ACTIVE

DEUTSCH | DEUTSCH HD, DEUTSCH HD30

TE Internal #: 114017-ZZ


Sealing Plug, PBT GF30, White, -55 – 125 °C [-67 – 257 °F]

Operating Temperature, DEUTSCH HD30

[View on TE.com >](#)



Connectors > Connector Accessories > Connector Seals & Cavity Plugs > DEUTSCH Sealing Plugs

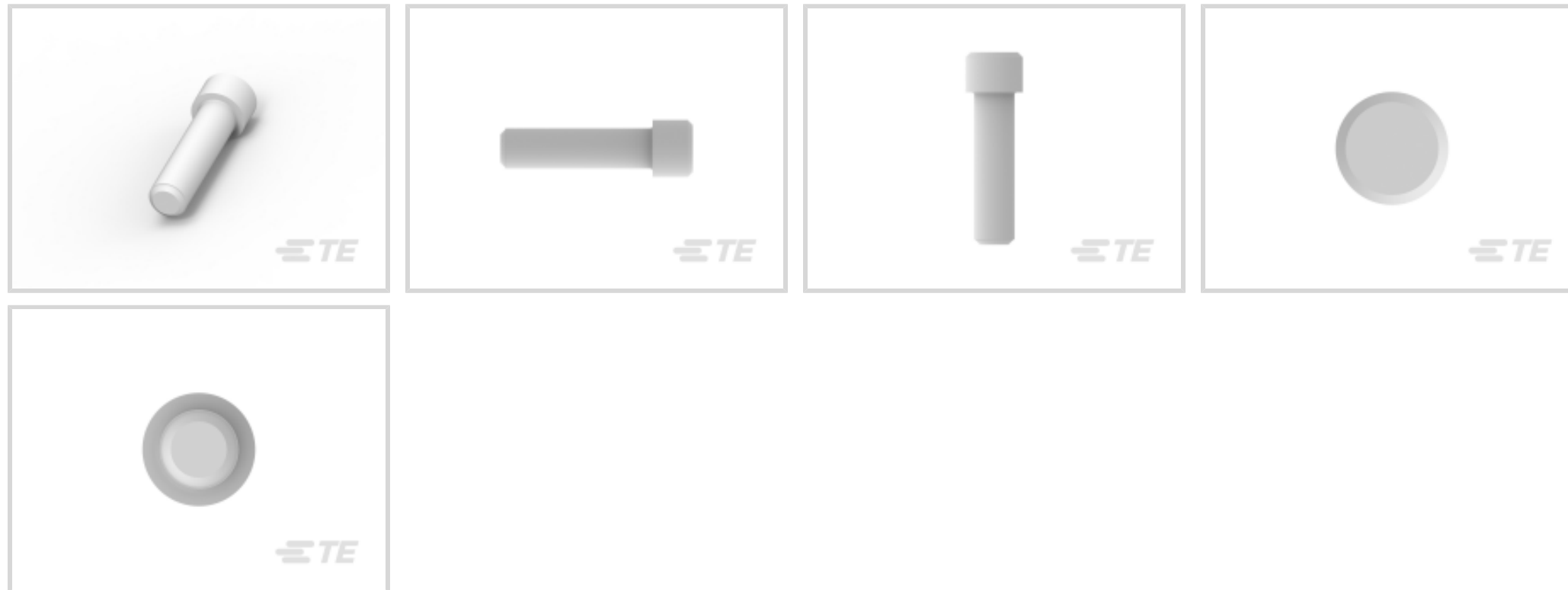

Connector Seal & Plug Type: **Sealing Plug**

Primary Product Material: **PBT GF30**

Primary Product Color: **White**

Operating Temperature (Max): **125 °C [257 °F]**

Contains Lubricant: **No**

[All DEUTSCH Sealing Plugs \(10\)](#)

Features

Product Type Features

Connector Seal & Plug Type	Sealing Plug
----------------------------	--------------

Body Features

Primary Product Material	PBT GF30
Primary Product Color	White

Usage Conditions

Operating Temperature (Max)	125 °C[257 °F]
Operating Temperature Range	-55 – 125 °C[-67 – 257 °F]

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Quantity	1
Packaging Method	Box



Other

Contains Lubricant	No
--------------------	----

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2024 (240) Candidate List Declared Against: JAN 2024 (240) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-H3930-CH8172
DEUTSCH HD30 Housings



TE Part # CAT-J41-DDRC
DEUTSCH DT Receptacle Connectors




TE Part # CAT-H396-CH8172
DEUTSCH HDP20 Housings



TE Part # CAT-J41-DDPC
DEUTSCH DT Plug Connectors




TE Part # CAT-D799-CH8172
DEUTSCH DRC Housings




TE Part # CAT-D781-CH8172
DEUTSCH DRB Housings




TE Part # CAT-H3910-CH8172
DEUTSCH HD10 Housings



TE Part # CAT-D486-CH8172
DEUTSCH DTP Housings



TE Part # CAT-ST858-CH8172
DEUTSCH Strike Housings



TE Part # CAT-D48-PCH8172
DEUTSCH DTHD Housings



TE Part # CAT-J41-DDCC
DEUTSCH DT Color Connectors



TE Part # DRCP28-86SB
PLG, 86P, BLK, 12/20, B



TE Part # CAT-D487-CH8172
DEUTSCH DT Series Housings & Connectors



TE Part # HD10-9-96P-N005
SQ FG REC ASM



TE Part # HDFB-16-06S
MODULE, FEEDBACK, 21P, GRAY, SZ16, SOC



TE Part # DTV06-18SC
PLG, 18P, GRN, N, C



TE Part # DTV06-18SA
PLG, 18P, GRY, N, A



TE Part # DTV06-18SB
PLG, 18P, BLK, N, B



TE Part # DTV02-18PA
REC, 18P, GRY, N, FLANGE, A




TE Part # DRCP28-86SA
PLG, 86P, BLK, 12/20, A


Also in the Series | **DEUTSCH HD**




Automotive Connector Caps & Covers (32)



Automotive Housings(768)



Connector Backshells(29)



Connector Seals & Cavity Plugs(10)




Connector Strain Relief(5)



Insertion & Extraction Tools(11)



Other Automotive Connector Accessories(11)

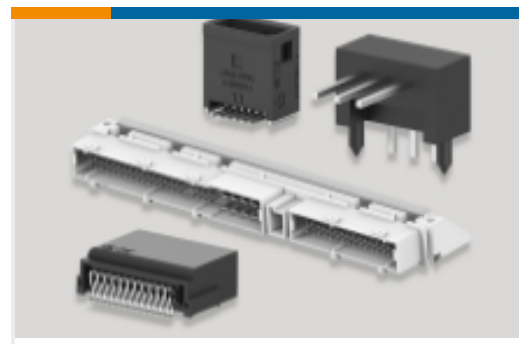


PCB Headers & Receptacles(1)

Also in the Series | DEUTSCH HD30



Automotive Connector Caps & Covers (14)

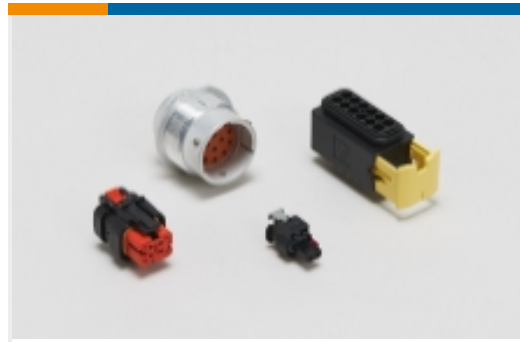

Automotive Housings(359)



Connector Backshells(2)



Connector Seals & Cavity Plugs(11)



Connector Strain Relief(5)



Insertion & Extraction Tools(10)



Other Automotive Connector Accessories(6)

Customers Also Bought



TE Part #DT06-4S
PLG, 4P, GRY, N



TE Part #W12P
Wedgelocks: DEUTSCH DT



TE Part #0460-215-16141
DEUTSCH Solid Contacts

Documents

Product Drawings

[SEALING PLUG, SIZE 12/16, WHT](#)

English

CAD Files

[3D PDF](#)



3D

Customer View Model

[ENG_CVM_CVM_114017-ZZ_C.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_114017-ZZ_C.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_114017-ZZ_C.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[ICT Terminals and Connectors Catalogue](#)

English

[CONNECTOR SELECTOR](#)

English

Product Specifications

[Application Specification](#)

English

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English