




# BU-4150003XXX

(Cable Assembly Coaxial SMB Straight to SMB Straight Male to Male RG-316)

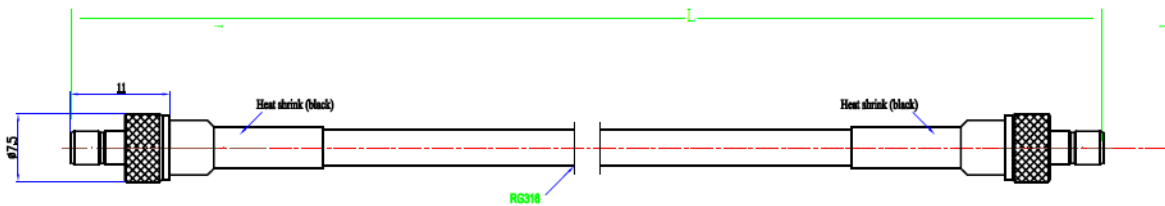

Mueller Electric Company  
2850 Gilchrist Rd. Bld 5A  
Akron, OH 44305

[www.muellerelectric.com](http://www.muellerelectric.com)

Toll Free: 800.955.2629  
Phone: 330.780.2525  
Fax: 330.780.2524

## Electrical Ratings

Electrical ratings of a cable assembly are determined by the limiting connector type and cable size.

Connector	Cable	Connector Impedance (Ohms)	Frequency (GHz)	VSWR	Working Voltage (At Sea Level)
SMB	RG-316	50	DC-4	1.35 MAX	335V

## Product Attributes

Gender	Male to Male
Style	SMB to SMB
1st Connector	Gold Plated SMB Male Plug Straight
2nd Connector	Gold Plated SMB Male Plug Straight
Features	Shielded
Operating Temperature	-65°C (-85°F) to 150°C (302°F)
BU-4150003006	6" (152.40 mm)
BU-4150003012	12" (304.8 mm)
BU-4150003018	18" (457.2 mm)
BU-4150003024	24" (609.6 mm)
BU-4150003036	36" (914.4 mm)
BU-4150003M1.0	1.0M (39.4")
BU-4150003MM500	500mm (19.7")
BU-4150003MM750	750mm (29.5")
RoHS 3 Compliant	