




## BU-4150059XXX

(Cable Assembly Coaxial SMA Straight to N-type Straight Male to Male RG-58)

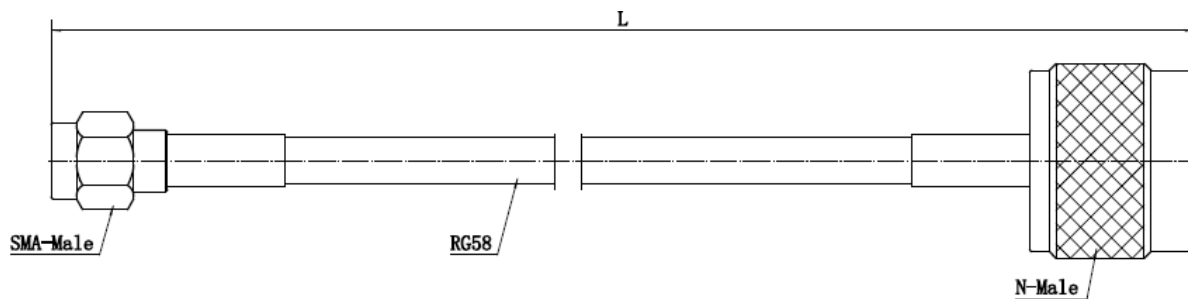

Mueller Electric Company  
2850 Gilchrist Rd. Bld 5A  
Akron, OH 44305

[www.muellerelectric.com](http://www.muellerelectric.com)

Toll Free: 800.955.2629  
Phone: 330.780.2525  
Fax: 330.780.2524

## Electrical Ratings

Electrical ratings of a cable assembly are determined by the limiting connector type and cable size.

Connector	Cable	Connector Impedance (Ohms)	Frequency (GHz)	VSWR	Working Voltage (At Sea Level)
SMA, N Type	RG-58	50	DC-3	1.2 MAX	335V

## Product Attributes

Gender	Male to Male
Style	SMA to N Type
1st Connector	Gold Plated SMA Male Plug Straight
2nd Connector	Nickel Plated N-type Male Plug Straight
Features	Shielded
Operating Temperature	-65°C (-85°F) to 150°C (302°F)
BU-4150059012	12" (304.8 mm)
BU-4150059024	24" (609.6 mm)
BU-4150059036	36" (914.4 mm)
BU-4150059048	48" (1219.2 mm)
BU-4150059060	60" (1524 mm)
BU-4150059M1.5	1.5M (59.1")
BU-4150059MM250	250mm (9.8")
BU-4150059MM500	500mm (19.7")
BU-4150059MM750	750mm (29.5")
RoHS 3 Compliant	